


Mechanical Specifications

D	22.8 mm Max
T	7.0 mm Max
Lead Diameter	0.8 mm Nom
S	7.2 mm Nom
L	30.0 mm Nom
B	3.0 mm \pm 1.0mm

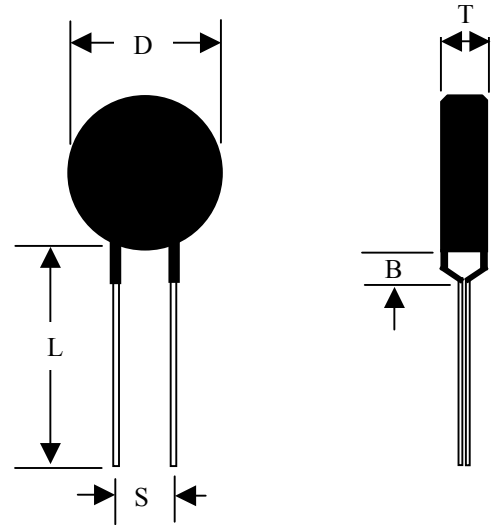

Electrical Specifications

Resistance @ 25°C	50.0 Ω \pm 25%
Transition Temp	120° C
Max voltage Rating	680 Vrms
Max Energy Rating	600J
Switch Current @ 25°C	0.450A
Continuous Current @ 25°C	0.225A
Heat Capacity	2.4 Joules/°C
Dissipation Constant	22.50 mW/°C
Thermal Time Constant	65.0 seconds
Max Body Temp. @ Max voltage	178°C

Ametherm, Inc
961 Fairview Dr.
Carson City, NV 89701
Telephone: **800-808-2434**
Fax: 775 884-0670
www.Ametherm.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Ametherm:](#)

[MCL20 500100-480](#)