


# T4 MINI TRIM SWITCHES


MT  
T4 MINI TRIM  
SWITCHES

## 4-WAY MINI TRIM, COMMERCIAL & MILITARY GRADES

The T4 Mini Trim is a single pole, 4 throw, center off, momentary contact (self return to center off). Numerous button styles are available on both the Commercial and Military grade switch versions. Mini Trims are typically press fit into control grips or panel mounted using versions with an 11/16" threaded case. Mini Trims are also available with multiple sealing levels to fit all applications.

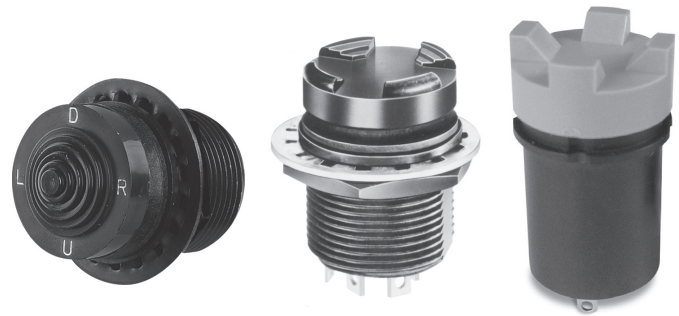


### Typical Dimensions

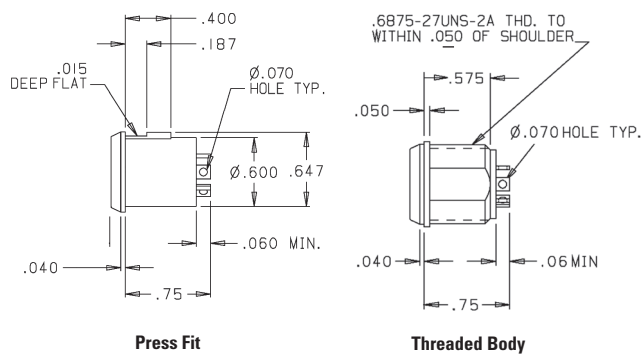

Press Fit

Threaded Body

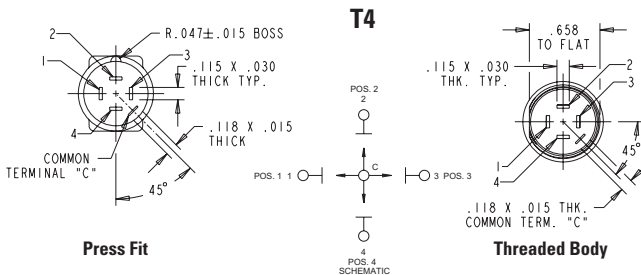

Press Fit

Threaded Body

### Standard Characteristics/Ratings:

#### ELECTRICAL RATINGS:

| Load                                    | Rating                                                                                                                                           |
|-----------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------|
| Resistive                               | 10mA @ 5VDC (low level)                                                                                                                          |
| Inductive                               | 1A @ 28VDC                                                                                                                                       |
| DWV                                     | 1050Vrms                                                                                                                                         |
| Low Level                               | 10mA Resistive @ 5VDC                                                                                                                            |
| <b>Electrical Life:</b>                 | 100,000 cycles 1A Inductive @ 28VDC                                                                                                              |
| <b>Lever Travel:</b>                    | 15° max from center OFF                                                                                                                          |
| <b>Seal:</b>                            | IP64 or IP68S or MIL-PRF-8805 Design 3                                                                                                           |
| <b>Operating Temp Range:</b>            | -55°C to +85°C                                                                                                                                   |
| <b>Operating Force:</b>                 | 16 oz +/- 6 oz                                                                                                                                   |
| <b>Lever Pivot &amp; Stop Strength:</b> | Switch is capable of withstanding a force of 25.0 lbs. applied to the actuating button. The button also withstands 15.0 lbs. minimum pull force. |

#### MATERIALS:

|                           |                                                                |
|---------------------------|----------------------------------------------------------------|
| <b>Case:</b>              | Aluminum alloy or thermoplastic                                |
| <b>Button:</b>            | Thermoplastic                                                  |
| <b>Terminals:</b>         | Silver over brass<br>Brass with gold over silver for low level |
| <b>Terminal Hardware:</b> | None provided                                                  |
| <b>Mounting Hardware:</b> | Hex nut, tooth lockwasher, panel seal gasket where applicable  |

### T4 MINI TRIM PART NUMBER CODE

| Series    | Grade                        | Button Style                                                                                                                                                                                         | Case Style                  | Seal Level                                                                                                                                    | Current Rating              | Button Color*                                        |
|-----------|------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------|-----------------------------|------------------------------------------------------|
| T4. 4-Way | C. Commercial<br>M. Military | A. 2-Way Jog<br>B. Tall Jog<br>C. Rocker<br>D. Cone<br>E. LRUD Hat<br>F. IOUD Hat<br>G. Hat<br>H. Stadium<br>J. Castle<br>K. 4-Way Jog<br>L. Short Bat<br>M. Bat<br>N. Post<br>P. 4-40 Threaded Post | 1. Press Fit<br>2. Threaded | 1. IP64 Dusttight<br>2. IP68S Watertight<br>3. Design Symbol 3 Watertight per MIL-PRF-8805 and Meets Environmental Testing per MIL-DTL-9419 ① | 1. Standard<br>2. Low Level | 1. Red<br>2. Black<br>8. Gray<br>N. Not Applicable** |

① Only available with military grade.

\* Contact factory for additional button colors.

\*\* Use when specifying button styles L, M, N and P.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[OTTO:](#)

[T4-ML132N](#) [T4-MP211N](#) [T4-MH1111](#) [T4-MJ1322](#) [T4-MD1112](#) [T4-MD2112](#) [T4-ME1111](#) [T4-MH2122](#) [T4-MJ1118](#)