

RECEPTACLE: WTBT 20 SAR7 SY  
 XXXX XX XXXX XX

**RECEPTACLE**

**SERIES**

WTBT Receptacle, right angle, with mounting ears

**SIZE**

XX Number of contacts (10, 14, 20, 24, 26, 30, 36, 40, 44, 50, 54, 56, 60, 66, or 70)

**CONTACTS**

**TYPE CONTACTS/TERMINATIONS:**

- SARC Socket, right angle, solder cup (.035" I.D.)
- SAR7 Socket, right angle, dip solder, .109" x .025" dia
- SAR9 Socket, right angle, dip solder, .140" x .025" dia
- SAR11 Socket, right angle, dip solder, .172" x .025" dia


**HARDWARE**

- SY Guide set
- J Fixed jackset
- JT Turning jackset, .475"
- JTA Turning jackset, .175"
- JTB Hex turning jackset, .175"
- JTC Hex turning jackset, .475"
- JTL Turning jackset, long, .675"

- WTBT connectors with "J" hardware will mate with: WTA\*\*\*\*JT  
 WTA\*\*\*\*JTA
- WTBT connectors with "SY" hardware will mate with: WTB\*\*\*\*SY  
 WTAV\*\*\*\*SY
- For polarized "D" shaped guides, add dash and code number to the part number (example: -7).  
 See "Polarization" in Accessories section for codes.

**OPTIONS**

- Option Codes: Add to the end of the part number. Example: WTBT10SAR9J-D01. Call factory for additional codes.
  - 342 Remove mounting ears (.250" each end)
  - D01 Pretinned contact terminations (except solder cups, wire wraps<sup>®</sup> and flex contacts) with 63/37 or 60/40 solder. ☒
  - P39 Pretinned contact terminations (except solder cups, wire wraps<sup>®</sup> and flex contacts) with SAC305 solder (lead free).
- ☒ = Option not RoHS compliant

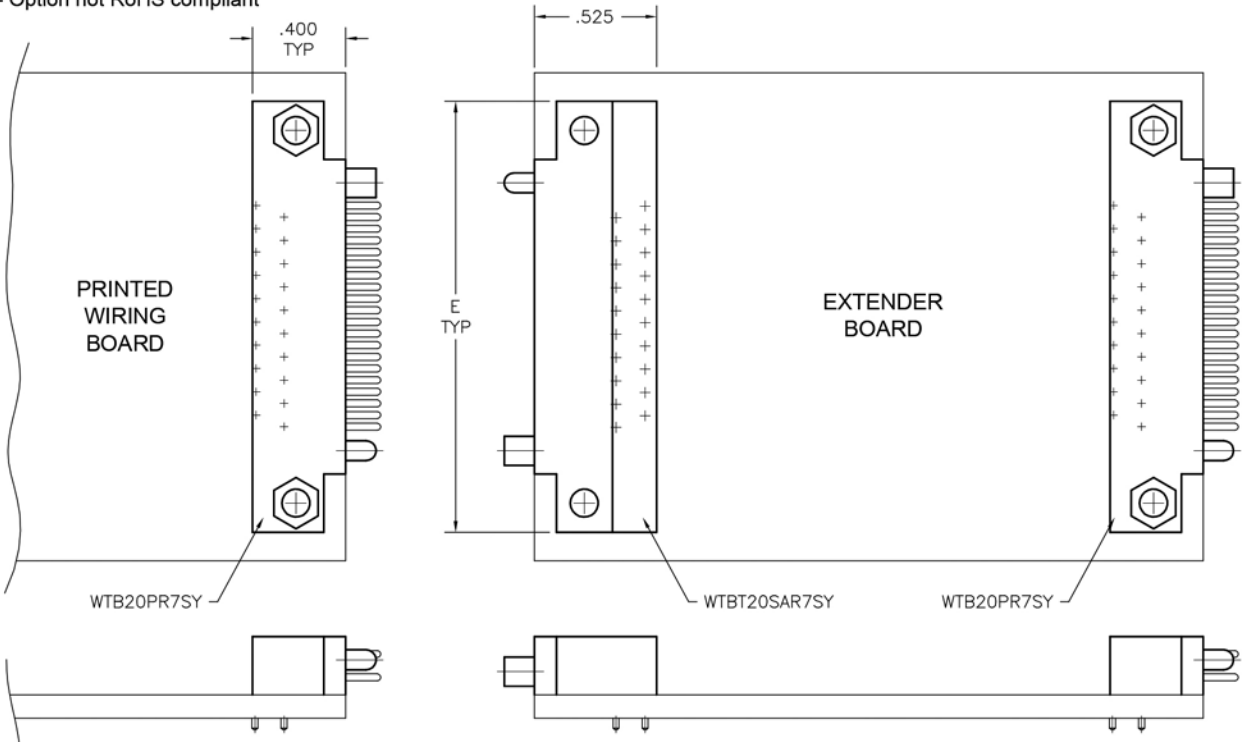

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AirBorn:](#)

[WTBT60SAR11SY-N54](#)