


# Actuator

45-  
2828.2C30.001

Distribution by  
Mouser

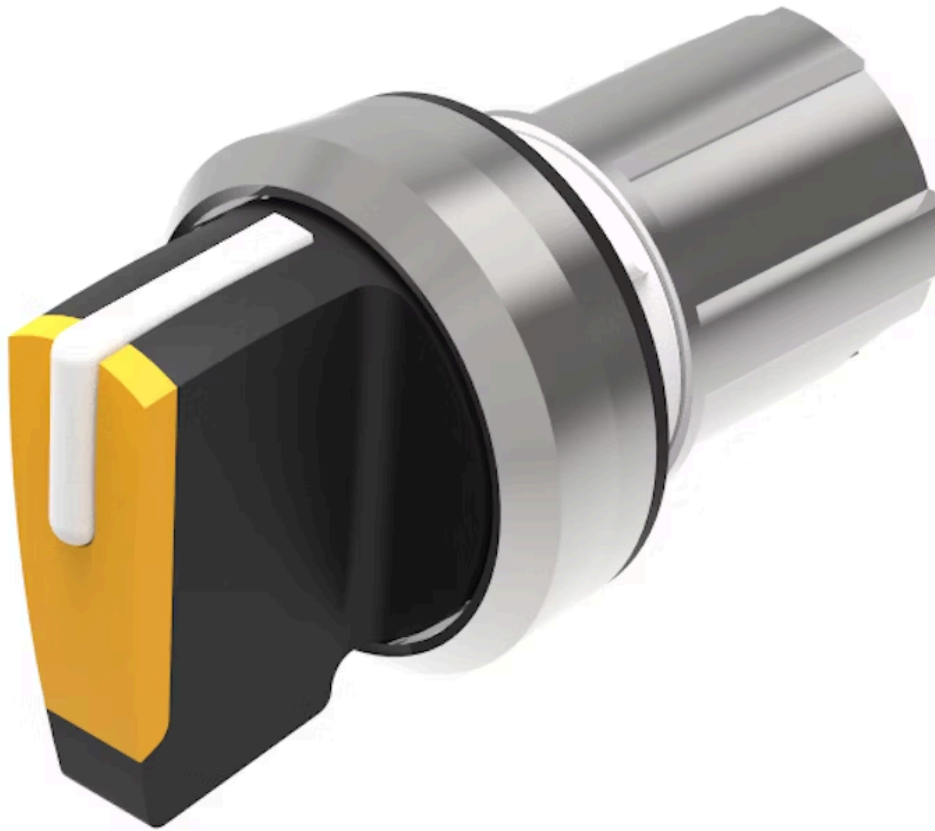

<https://mouser.eao.com/p/45-2828.2C30.001>

Your product:

---



## 45-2828.2C30.001 Actuator

### FRONT

|                              |           |
|------------------------------|-----------|
| <b>Front dimension:</b>      | Ø 29,5 mm |
| <b>Front form:</b>           | round     |
| <b>Front bezel colour:</b>   | Silver    |
| <b>Front bezel material:</b> | Metal     |

### MOUNTING

|                          |                |
|--------------------------|----------------|
| <b>Design:</b>           | raised         |
| <b>Mounting cut-out:</b> | Ø 22.3 mm      |
| <b>Mounting type:</b>    | Panel mounting |

### OPERATING-/INDICATION PART

|                        |         |
|------------------------|---------|
| <b>Lever colour:</b>   | Amber   |
| <b>Lever material:</b> | plastic |
| <b>Lever shape:</b>    | short   |

### MECHANICAL CHARACTERISTIC

|                             |                            |
|-----------------------------|----------------------------|
| <b>Switching action:</b>    | Rest - Maintained          |
| <b>Switching positions:</b> | 2 positions                |
| <b>Switching angle:</b>     | 90° right / -45° ... +45°  |
| <b>Mechanical lifetime:</b> | 1 Mio. cycles of operation |
| <b>Operating frequency:</b> | 1 800/h                    |
| <b>Weight:</b>              | 0.051 kg                   |

## AMBIENT CONDITION


|                               |  |
|-------------------------------|--|
| <b>IP front protection:</b>   | IP66, IP67, IP69K  |
| <b>Operating temperature:</b> | - 25 °C ... + 70 °C  |
| <b>Storage temperature:</b>   | - 40 °C ... + 80 °C  |
| <b>Shock resistance:</b>      | According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms |
| <b>Vibration resistance:</b>  | According to IEC 60068-2-6: 10 ... 500 Hz: 5 g                 |
| <b>Climate resistance:</b>    | During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6    |

## CERTIFICATE


|               |                 |
|---------------|-----------------|
| <b>REACH:</b> | REACH compliant |
| <b>RoHS:</b>  | RoHS compliant  |

## OTHER


|                             |   |
|-----------------------------|---|
| <b>Short Description:</b>   | Actuator, Ø 22.3 mm, Ø 29,5 mm, optional illuminative, Amber, short, round, Silver, Metal, Rest - Maintained, IP66, IP67, IP69K |
| <b>Housing material:</b>    | Metal   |
| <b>Hints:</b>               | External diameter of the short lever 32.3 mm  |
| <b>Switching positions:</b> |   |

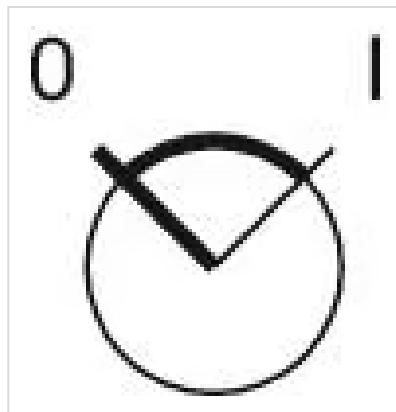


## Wiring diagrams:

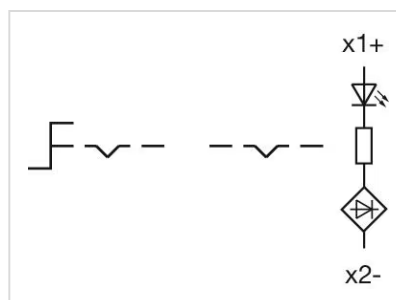

**Mounting cut-outs:**

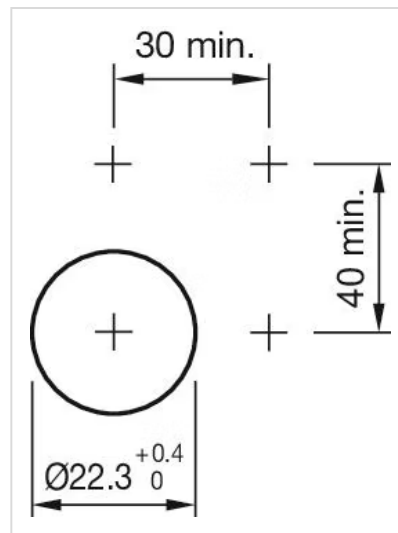

**Dimension drawings:**

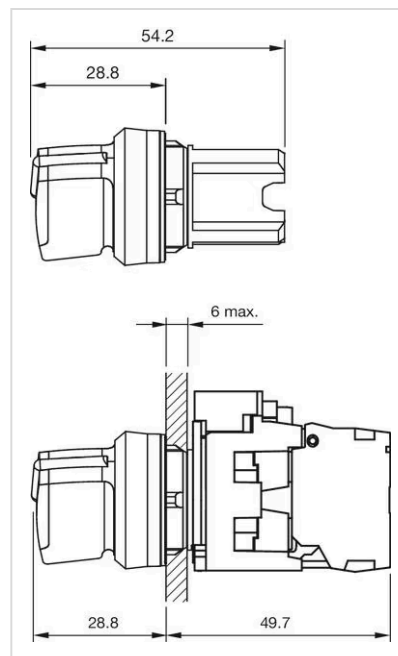

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2828.2C30.001](#)