

Actuator

46-
2736.4920.000

Distribution by
Mouser



<https://mouser.eao.com/p/46-2736.4920.000>

Your product:



46-2736.4920.000

Actuator

FRONT

Front dimension:	Ø 40 mm
Front form:	round
Front bezel colour:	Silver
Front bezel material:	Aluminium

MOUNTING

Design:	flush
Mounting cut-out:	Ø 30.5 mm
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Lens colour:	Red
Lens material:	Plastic
Lens illumination:	non illuminative
Lens shape:	mushroom-head
Lens optics:	opaque

ELECTRICAL CHARACTERISTICS

Protection class:	I
-------------------	---

MECHANICAL CHARACTERISTIC

Release type:	Twist to unlock
---------------	-----------------

Mechanical lifetime:	50 000 cycles of operation
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Weight:	0.05 kg

AMBIENT CONDITION


IP front protection:	IP65
IK front protection:	IK03
Operating temperature:	– 25 °C ... + 55 °C
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE


Approbations:	CSA, UL
Conformities:	CE
REACH:	REACH compliant
RoHS:	RoHS compliant
Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850

OTHER

Short Description:	Actuator, Ø 30.5 mm, Ø 40 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, Silver, Aluminium, IP65, IK03, Twist to unlock
Dimension:	Ø 40 mm
Housing colour:	Black
Housing material:	Plastic
max. number of switching elements:	4
Mounting cut-outs:	

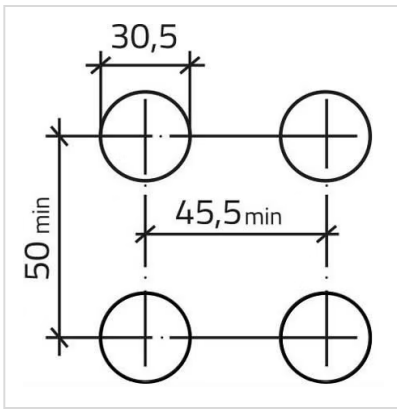

Dimension drawings:

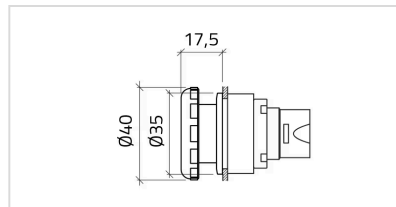

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[46-2736.4920.000](#)