

Actuator

61-
0010.02



<https://eao.com/p/61-0010.02>

Your product:



61-0010.02 Actuator

FRONT

Front dimension:	Ø 18 mm
Front form:	round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Mounting cut-out:	Ø 16 mm
Mounting type:	Panel mounting

MECHANICAL CHARACTERISTIC

Terminal:	Plug-in terminal, 2.8 x 0.5 mm
Tightening torque:	Max. 0.5 Nm
Weight:	0.005 kg

AMBIENT CONDITION

IP Protection:	IP40 rear side, according to EN IEC 60529, IP67 front side, according to EN IEC 60529
Operating temperature:	- 25 °C ... + 55 °C
Storage temperature:	- 40 °C ... + 85 °C

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER


Short Description: Actuator, Ø 16 mm, Ø 18 mm, round, Black, Plastic, Plug-in terminal, 2.8 x 0.5 mm

Internal size: Ø 15,8 mm


Housing colour: Black

Housing material: Plastic, according to UL 94 V0, self-extinguishing


Wiring diagrams:

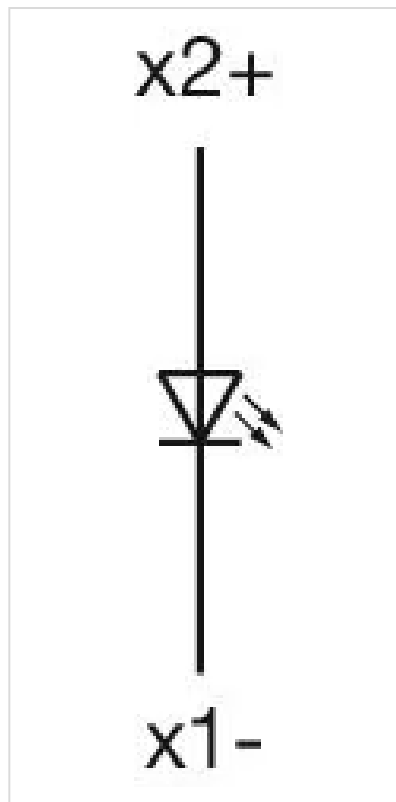



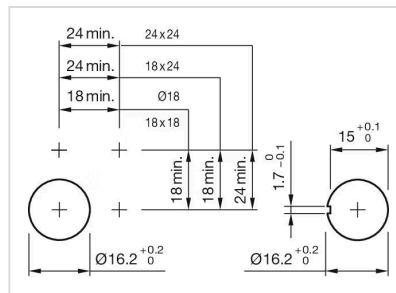



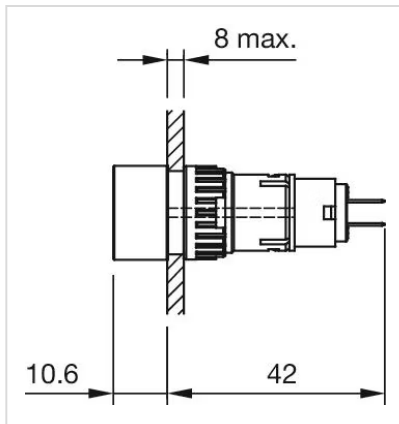



Mounting cut-outs:



Dimension drawings:



Where to Buy

	Distributor	Quantity in Stock	
	RS UK	34 in stock	Buy 
	RS Americas	32 in stock	Buy 
	Mouser Electronics	20 in stock	Buy 
	Transfer Multisort Elektronik	11 in stock	Buy 
	Digi-Key	8 in stock	Buy 

[Show more](#) 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[61-0010.02](#)