
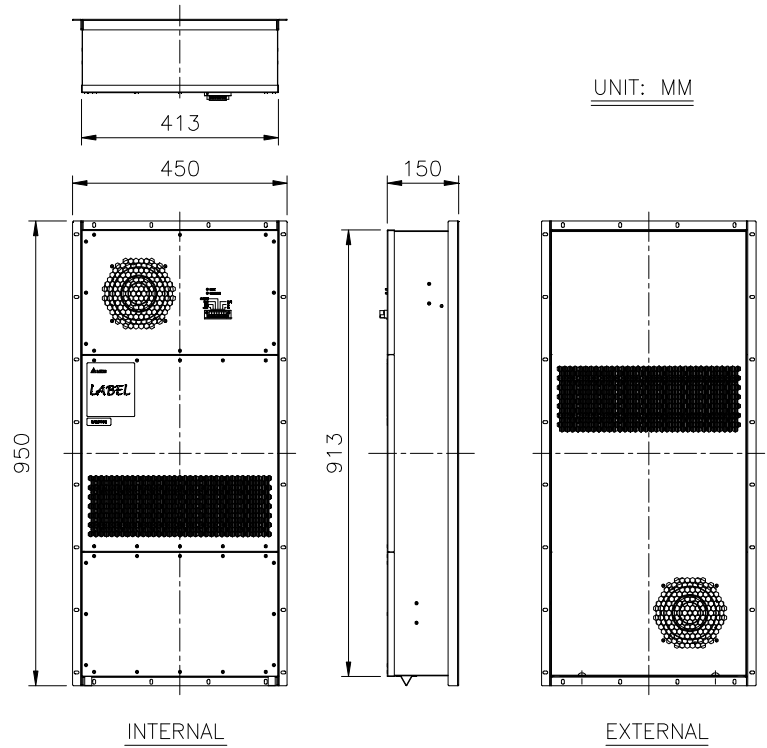


## Internal Door mount

## HEX080PD series

### Dimension drawing

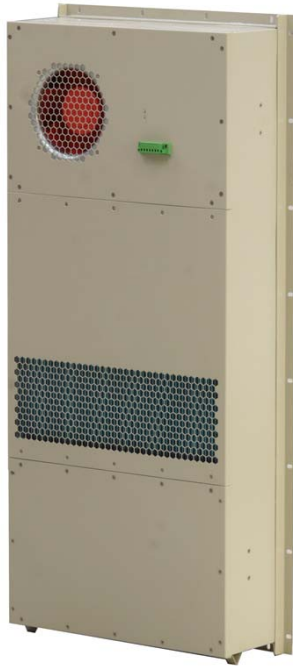

### Features

- ◆ IP55 waterproof at external side
- ◆ Standalone temperature control
- ◆ RS-485 function
- ◆ Clear LED status indicator
- ◆ Dry contact alarm output

### Design

- ◆ Air to air heat exchange
- ◆ Rated voltage at 48V
- ◆ High efficiency and reliable fan
- ◆ Easy installation and maintenance

Main feature	Unit	Specification
Dimension (H x W x D)	mm (in)	950 x 450 x 150 (37 x 18 x 6)
Cooling capacity* <sup>Note</sup>	W/K (W/°F)	80 (44)
Rated voltage	VDC	48
Operating current	A	2.2
Operating power	W	106
Operating voltage range	VDC	40 ~ 60
Operating temperature range	°C	-10 ~ +65
Noise (1.5 meter)	dB-A	65.0
Weight	Kg (Lb)	19 (42)

\* Note : The cooling capacity (W/K , W/°C or W/°F) is defined as  $Q / (T_i - T_A)$

Q : Heat dissipation (W) from inside of cabinet

$T_i$  : Return temperature of internal air circuit (K , °C or °F)

$T_A$  : Ambient temperature of external air circuit (K , °C or °F)

\* Specifications are subject to change without notice.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delta Electronics:](#)

[HEX080PD](#)