


Wall mount

HEC1200PB series

Dimension drawing

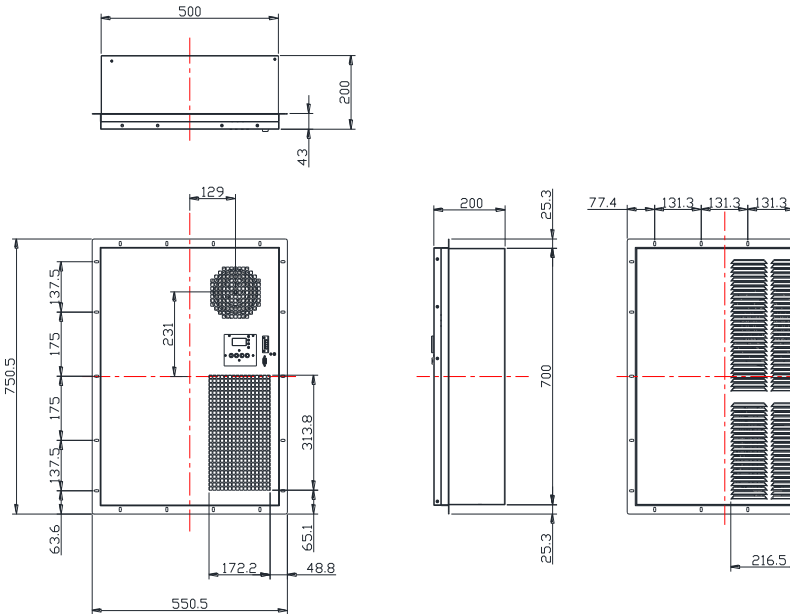

Features

- ◆ Reliable and energy efficient thermal solutions.
- ◆ Energy efficient fans and effective compressor.
- ◆ IP55 waterproof at external side.
- ◆ Precise temperature control.
- ◆ Earth-friendly refrigerant.
- ◆ Dry contact alarm output.

Design

- ◆ Compact size.
- ◆ Rated voltage at 48V.
- ◆ Built-in smart controller.
- ◆ High efficiency and reliable fan.
- ◆ Easy installation and maintenance.

Main feature	Unit	Specification
Dimension (H x W x D)	mm (inch)	700 x 500 x 200 (27.7 x 19.8 x 7.9)
Cooling capacity ^{*Note}	W (BTU/hr)	1200 (4080)
Rated voltage	VDC	48
Operating current	A	7.9
Operating voltage range	VDC	40 ~ 58
Operating temperature range	°C	-10 ~ +55
Noise (1.0 meter)	dB-A	65.0
Weight	Kg (Lb)	28 (61.7)

* Note : L35/L35

* Specifications are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Delta Electronics:](#)

[HEC1200PB](#)