

# 96PSA-A120W24T2

Adapter Power Supply



## Features

- Full range AC input 90V~264V
- Meet Energy Star EPS 2.0 /ErP Lot 7
- No load Power Consumption  $\leq 0.21W$
- High Reliability
- Available for high altitude(5,000M) and DOE level VI

## General

Advantech Part Number	96PSA-A120W24T2
Description	FSP A/D 100240V 120W 24V Adapter
Manufacturer	FSP Technology

## Output Specifications

Output Power	120W
Output Voltage & Current	24VDC@5A
Efficiency (%)	100Vac / 5A load $\geq 87\%$ 240Vac / 5A load $\geq 89\%$
Main Connector	Signal

## Mechanical

Form Factor	N/A
Dimension (L x W x H)	151.3x75.6x25.4mm
Vibration	0.01g <sup>2</sup> /Hz at 5 Hz
MTBF	200,000 hours at 25°C
Fan Function	NO
Power Switch Function	NO

# Input Specifications

Input Voltage Range	100 - 240V
Input Current	100Vac, 240Vac / 5A load $\leq$ 1.8A
Input Frequency	4763Hz
PFC Function	W/PFC
Input Current Type	AC to DC


# Environmental Specification

Storage Temp.	-20 to +80°C
Storage Humidity	10 – 90% RH
Operating Temp. (°C)	0 to + 40°C

# Safety

Safety & EMC	Class B
Max Temp. (°C) @ Load	70C @ 86%
Safety Standard	CUL (UL 60950) / CB (IEC 60950) / CCC / CE / FCC / GS (EN 60950) / PSE / Efficiency Level VI
RoHs	YES

# Drawing

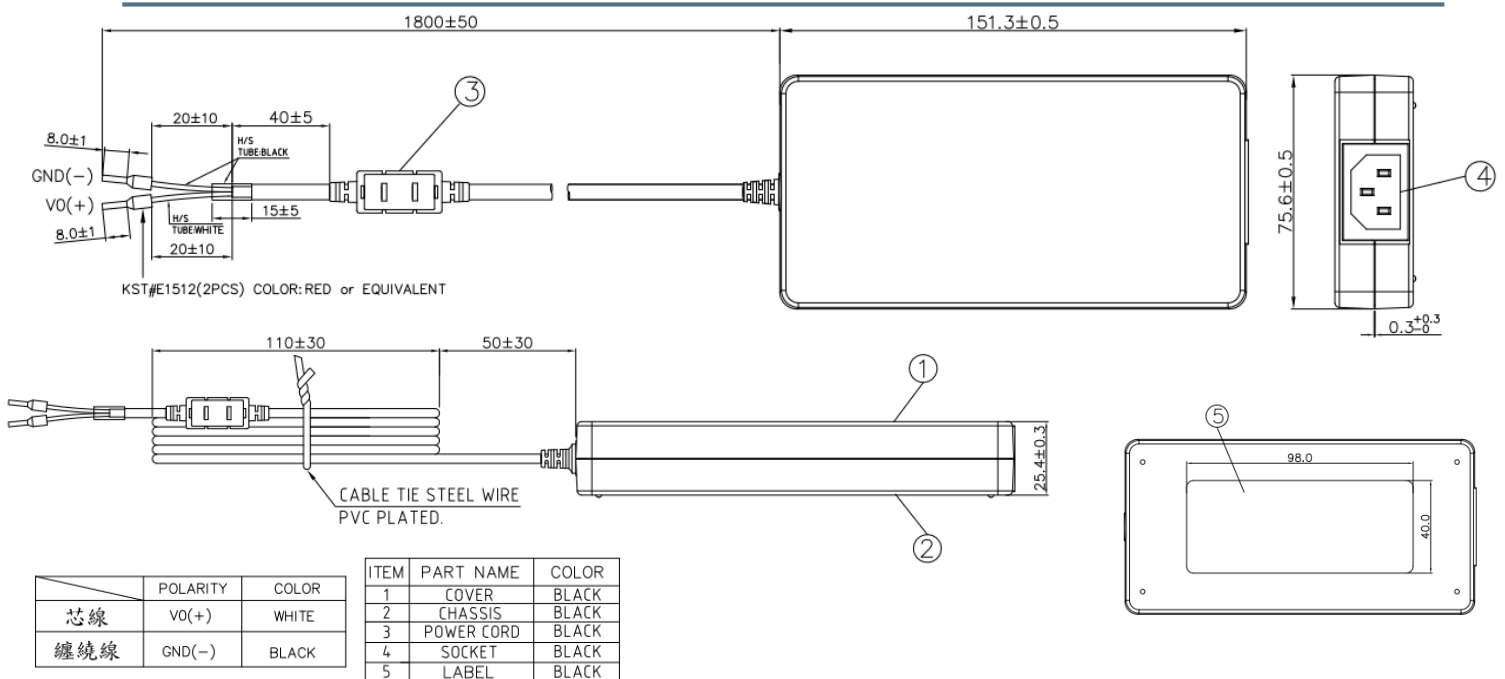

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[96PSA-A120W24T2-4](#)