

ITA-2230

Intel® Core™ i7 Fanless 2U Rackmount System with 3 ITAM Module



Features

- Built-in Intel® Core™ i7-3555LE, 2.5 GHz CPU
- Onboard 4GB DDR3 Memory
- 2U Fanless Rackmount System
- Support 3 ITAM Module for I/O expansion
- Support Easy-Swap Power Module
- 4 USB 3.0 & 4 USB 2.0
- HDMI & VGA Display output
- Compliance with railway applications (EN50121-4)




System Specifications


Processor System	CPU	Intel® Core™ i7-3555LE(25W)		
	Max Speed	2.5 GHz		
	L2 Cache	6 MB		
	Chipset	Intel® HM76		
	BIOS	AMI SPI 16 Mb		
Memory	Technology	DDR3 1600		
	Max. Capacity	Onboard 4 GB		
Graphics	Chipset	Intel® HD4000		
	VRAM	Shared system memory up to 512 MB SDRAM		
	Dual display	1 x VGA, 1 x HDMI, 1 x eDP (Optional)		
Ethernet	Interface	10/100/1000 Mbps		
	Controller	2 x Intel® I210IT		
	Connector	2 x RJ-45		
Storage	SSD	1 x Full size mSATA		
	HDD	1 x 3.5" or 2 x 2.5" HDD bay		
I/O Interface	VGA	1		
	HDMI	1		
	LAN	2		
	USB	4 x USB 3.0, 4 x USB 2.0		
	Serial	2 x DB9 (RS-232/422/485)		
	Digital I/O	1 x 8-ch TTL GPIO		
	Audio	1 x Speaker-out with 2 x4W Amp, 1 x Mic-in		
Expansion Slots	ITAM Slot	3		
	PC104+	1		
	Mini PCIe	1		
Power module		Single Power Module	Dual Power Module	
	Input Range	AC 100 ~ 240V or DC 110V	Dual AC 100 ~ 240V or DC 110V	
	Connector	1 x 3pin 5.08mm Terminal Block	2 x 3pin 5.08mm Terminal Block	
	Wattage (60° C)	110 W	110W (Load Balance)	
Watchdog Timer	Output	System Reset		
	Interval	Programmable 1~255 sec/min		
Environment		Operating (With SSD)	Operating (With HDD)	Non-Operating
	Temperature	-25 ~ 60° C	0 ~ 40° C	-40 ~ 85° C
Physical Characteristics	Dimensions (W x H x D)	427 x 88 x 325 mm		
Certification	EMC	CE/FCC Class A		
	Safety	UL,CB,CCC		
	Compliance	EN 50121-4,Level 4 EMS		

Dimensions


Unit: mm

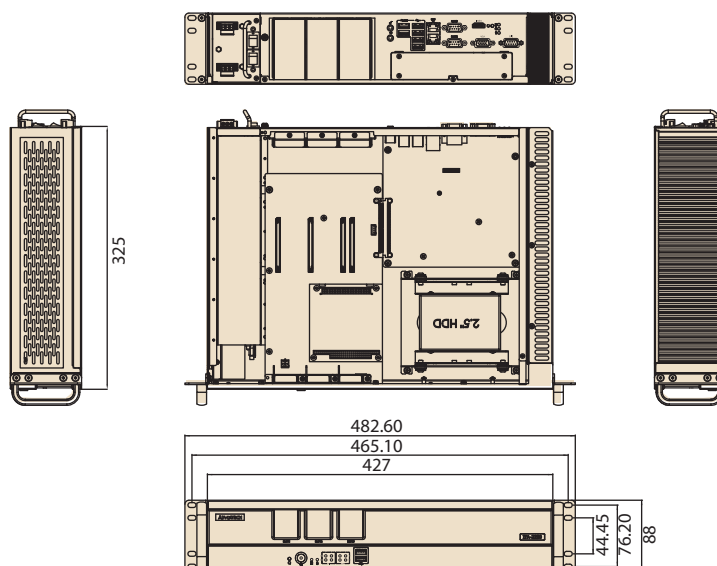

Front View

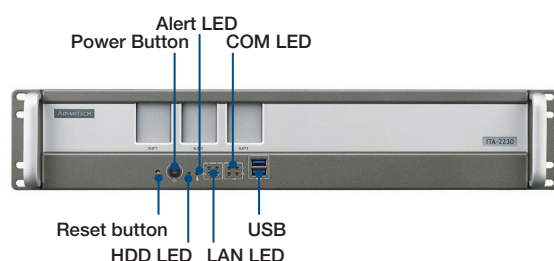

Rear View

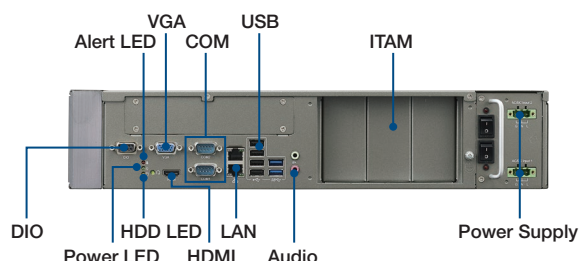

Packing List

Part No.	Description	Quantity
200K223000	Startup manual	1
206K223000	Driver CD	1
1700008941	SATA cable*7P	2
1700017929	SATA power cable*4P	1
1700022322-01	SATA power cable*5P	1
1990001365	HDD rubber	4
1960018229N100	2.5" HDD bracket	2
1656303100	Terminal block*3P	2
1960018229N100	2U Rack mount ear	2
1960021557S000	Handle bracket	2

Ordering Information


Part No.	Description
ITA-2230-00A1E	Intel Core i7, 4G on board memory, Single AC/DC power input 2U Rackmount
ITA-2230-10A1E	Intel Core i7, 4G on board memory, Dual AC/DC power input 2U Rackmount

Optional Accessories

Part No.	Description
ITAM-SR01-10A1E	8-port RS-232/422/485 ITAM Module
ITAM-SR01-00A1E	8-port RS-232/422/485 ITAM Module with 2.5KV isolation
ITAM-NC01-C0A1E	8-port GbE ITAM Module with RJ45 connector
ITAM-NC02-C0A1E	4-port GbE ITAM Module with RJ45 connector
ITAM-NC02-F0A1E	4-port GbE ITAM Module with SFP connector
1700023045-01	A Cable POWER 3P(F)/1*3P-5.08 10cm for ITA-2210

ITAM I/O Module & Power Module

Through ITAM I/O module to get LAN & Serial's amount expansion, it's for customer optional requirement. Pic shows in below:

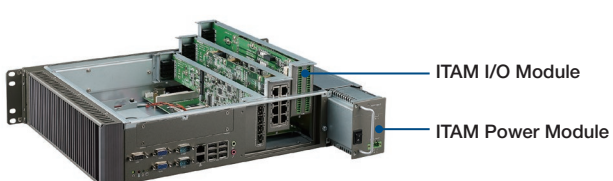

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[ITA-2230-00A1E](#) [ITA-2230-10A1E](#)