


NMC-0804

8 Ports 1GbE Fiber Module

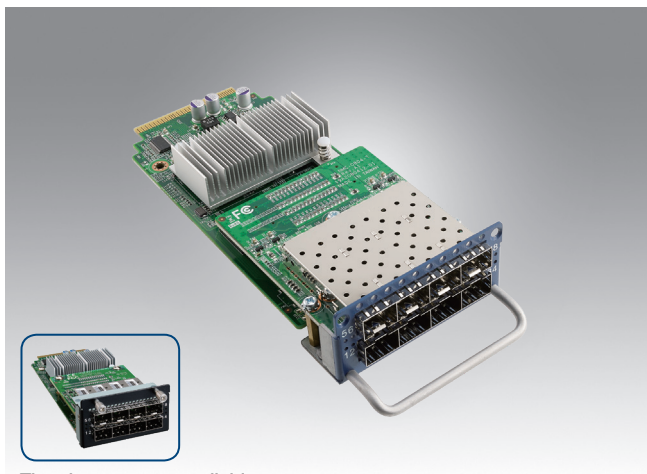

Thumbscrew type available now

Features

- 2x Intel i350_AM4
- 8 ports SFP connector
- 2x PCI-E 2.0 x4
- RoHS compliant

CE FCC RoHS COMPLIANT 2002/95/EC

Specifications

Controller	2x Intel i350_AM4
Interface	2x PCI-E 2.0 x4
Speed	1GbE
Port	8x SFP
LAN LED definition	10Mbps: LED off 100Mbps: LED on (Amber) 1000Mbps: LED on (Green) Link: LED on Act: Blinking
Advanced Software Features	Teaming support IEEE 802.3ad IEEE 802.1Q VLANs IEEE 802.3 2005 flow control support Interrupt moderation
OS Support	Windows® Server 2012 R2, 2012, 2008 R2 X86-64 Linux RedHat EL 6.5 and 7.0 IA-32, X86-64, and IA-64 Linux SuSE SLES 11 SP3 and 12 IA-32, X86-64, and IA-64 FreeBSD 9 and 10 IA-32, X86-64, and IA-64 UEFI 2.1 and 2.3 X86-64 and I-64 VMware ESXi 5.1, ESXi 5.5 and ESXi 6.0 X86-64
Operating Conditions	Operation: 0 ~ 40 °C Storage: -20 ~ 67 °C
Power Voltage & consumption	+12V ± 15% 16W
Dimension (mm)	163.7 x 74.6 x 35.5 (Latch type), 175 x 74.5 x 42.5 (Thumbscrew type)
Compliance	CE/FCC


Ordering Information

Part Number	Type	Description
NMC-0804E	Handle	8-ports 1GbE SFP w/ 2x Intel i350_AM4 NMC
NMC-0804-08FSA1	Thumbscrew	8-ports 1GbE SFP w/ 2x Intel i350_AM4 NMC


Dimensions

Unit: mm

Latch type

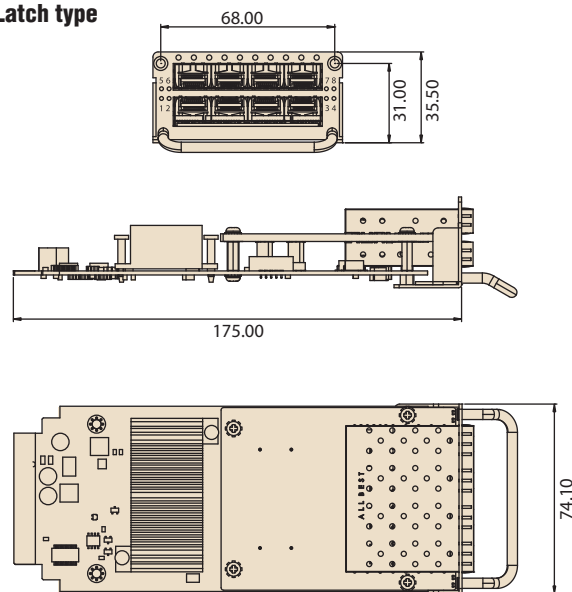

Thumbscrew type

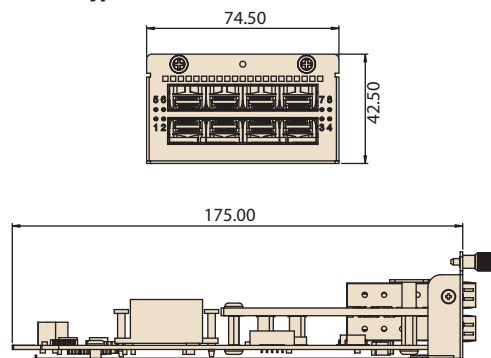

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Advantech:](#)

[NMC-0804-08FSA1](#)