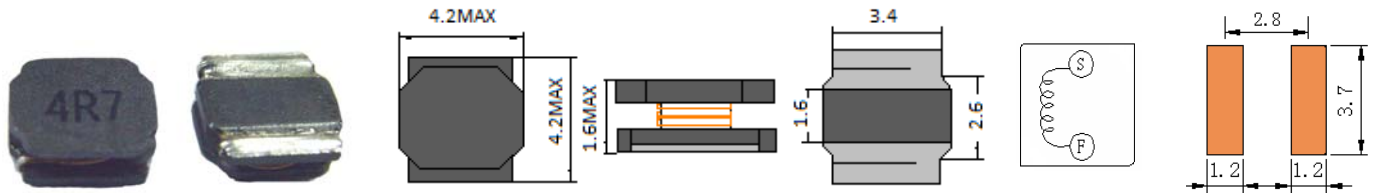


SMD POWER INDUCTORS

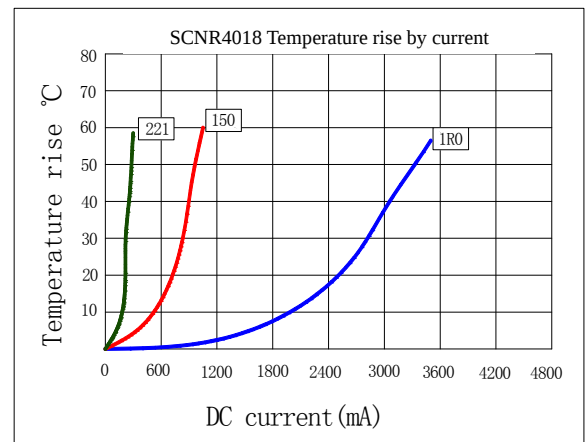
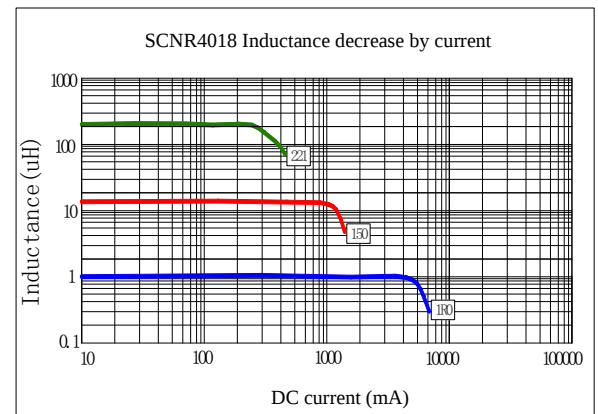


- Features

- ### 1. Open frame construction.



ELECTRICAL CHARACTERISTICS

[illegible]

(1). Inductance tested at 0.25V, 0ADC and 25°C.

Tolerance of inductance: $1.0\mu\text{H} \pm 30\%$ (N).

2.2uH-220uH: $\pm 20\%$ (M).

(2).DCR measured at 25°C.

(3). The DC current at which the inductance decreases by 30% from its initial value.

(4). The DC current that results in a 40°C temperature rise from 25°C ambient.

[Click here for QUANTITY PER REEL & PACKING INFORMATION](#)

Custom versions available upon request.

©2011 Signal Transformer – Specification subject to change without notice. 07.11

500 Bayview Avenue, Inwood, NY 11096

Toll Free 866-239-5777 • Tel 516-239-5777 • Fax 516-239-7208

Sales@signaltransformer.com • techhelp@signaltransformer.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bel:

[SCNR4018-100](#) [SCNR4018-470](#) [SCNR4018-151](#) [SCNR4018-680](#) [SCNR4018-3R3](#) [SCNR4018-330](#) [SCNR4018-1R0](#) [SCNR4018-101](#) [SCNR4018-221](#) [SCNR4018-4R7](#) [SCNR4018-220](#) [SCNR4018-6R8](#) [SCNR4018-2R2](#)
[SCNR4018-150](#)