

Stewart Connector

M5 Series

Connectors and Cable Assemblies

M5 connectors and cables are the smallest and lightest of the M Series and are ideal for sensor and many other applications where a compact, versatile, and rugged connector solution is needed to deliver a secure and seamless signal transfer.

This product line is IP67 rated when installed, adding to the reliable nature of these connectors in harsh environments.

Features & Benefits

- Water Resistance IP67
- A-Code, 4 Positions
- PUR Cable Jacket



Applications

- Harsh Environments
- Wet Environments
- Industrial
- Sensors and security
- Other applications with extreme space limitations



M5 Series


Connectors and Cable Assemblies

Connectors

Part Number	Gender	Performance	Interface	Type	Termination
SS-12600-001	Male	IP67	Receptacle	Rear Panel Mount	Solder Cup
SS-12600-002	Male	IP67	Receptacle	Rear Panel Mount	PCB
SS-12600-003	Female	IP67	Receptacle	Rear Panel Mount	PCB
SS-12600-004	Male	IP67	Plug	Overmolded	Solder

Cable Assemblies

BC - M5 A B C D E F G xxx M

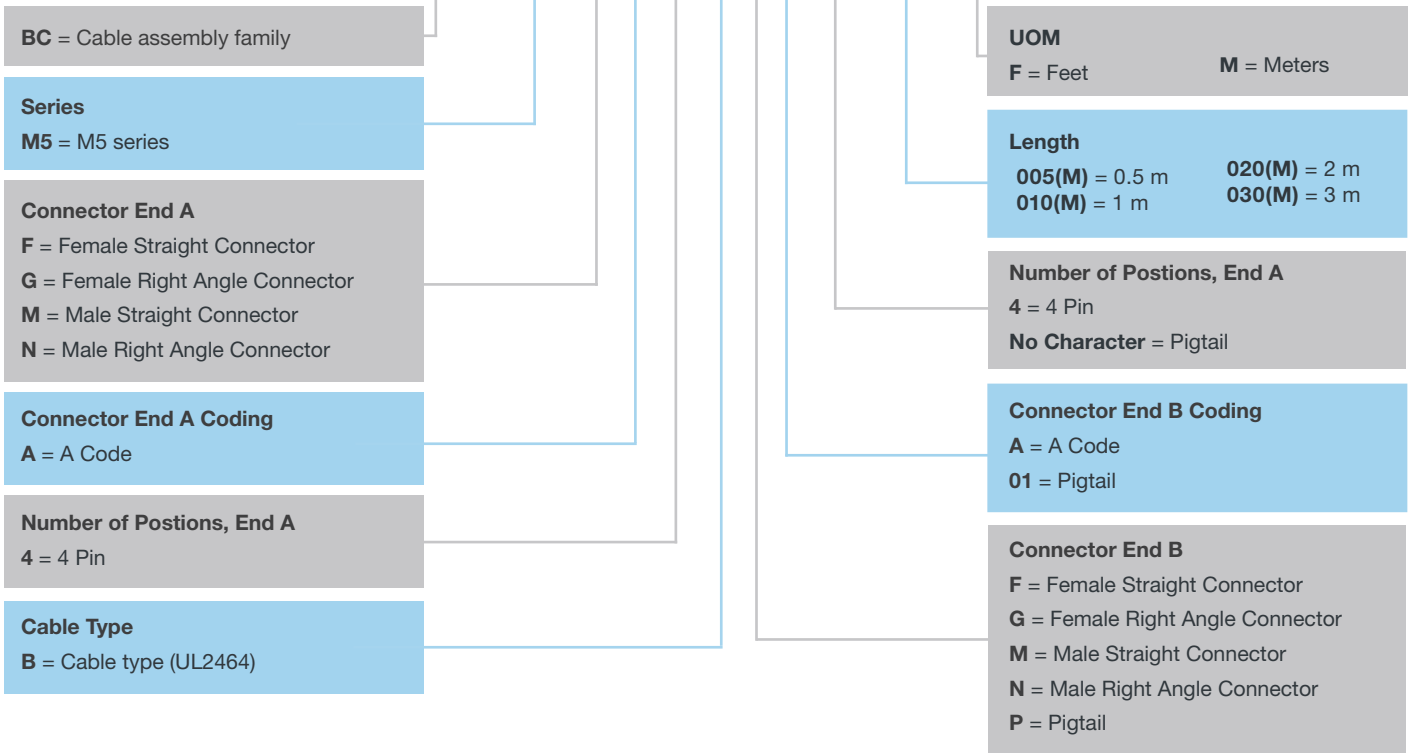

M5 Series

Cable Assemblies

Stewart Connector

Part Number	Positions	Performance	Connector End A	Connector End B	Lengths Available	
					ft	m
BC-M5FA4BFA4005M	4	IP67	M5 Female Straight	M5 Female Straight	1.64 ft	0.5 m
BC-M5FA4BFA4010M	4	IP67	M5 Female Straight	M5 Female Straight	3.28 ft	1 m
BC-M5FA4BFA4020M	4	IP67	M5 Female Straight	M5 Female Straight	6.56 ft	2 m
BC-M5FA4BFA4030M	4	IP67	M5 Female Straight	M5 Female Straight	9.84 ft	3 m
BC-M5FA4BMA4005M	4	IP67	M5 Female Straight	M5 Male Straight	1.64 ft	0.5 m
BC-M5FA4BMA4010M	4	IP67	M5 Female Straight	M5 Male Straight	3.28 ft	1 m
BC-M5FA4BMA4020M	4	IP67	M5 Female Straight	M5 Male Straight	6.56 ft	2 m
BC-M5FA4BMA4030M	4	IP67	M5 Female Straight	M5 Male Straight	9.84 ft	3 m
BC-M5MA4BMA4005M	4	IP67	M5 Male Straight	M5 Male Straight	1.64 ft	0.5 m
BC-M5MA4BMA4010M	4	IP67	M5 Male Straight	M5 Male Straight	3.28 ft	1 m
BC-M5MA4BMA4020M	4	IP67	M5 Male Straight	M5 Male Straight	6.56 ft	2 m
BC-M5MA4BMA4030M	4	IP67	M5 Male Straight	M5 Male Straight	9.84 ft	3 m
BC-M5MA4BP01005M	4	IP67	M5 Male Straight	Pigtail	1.64 ft	0.5 m
BC-M5MA4BP01010M	4	IP67	M5 Male Straight	Pigtail	3.28 ft	1 m
BC-M5MA4BP01020M	4	IP67	M5 Male Straight	Pigtail	6.56 ft	2 m
BC-M5MA4BP01030M	4	IP67	M5 Male Straight	Pigtail	9.84 ft	3 m
BC-M5FA4BP01005M	4	IP67	M5 Female Straight	Pigtail	1.64 ft	0.5 m
BC-M5FA4BP01010M	4	IP67	M5 Female Straight	Pigtail	3.28 ft	1 m
BC-M5FA4BP01020M	4	IP67	M5 Female Straight	Pigtail	6.56 ft	2 m
BC-M5FA4BP01030M	4	IP67	M5 Female Straight	Pigtail	9.84 ft	3 m
BC-M5GA4BP01005M	4	IP67	M5 Female Right Angle	Pigtail	1.64 ft	0.5 m
BC-M5GA4BP01010M	4	IP67	M5 Female Right Angle	Pigtail	3.28 ft	1 m
BC-M5GA4BP01020M	4	IP67	M5 Female Right Angle	Pigtail	6.56 ft	2 m
BC-M5GA4BP01030M	4	IP67	M5 Female Right Angle	Pigtail	9.84 ft	3 m
BC-M8NA4BP01020M	4	IP67	M5 Male Right Angle	Pigtail	1.64 ft	0.5 m
BC-M8NA4BP01030M	4	IP67	M5 Male Right Angle	Pigtail	3.28 ft	1 m
BC-M8NA4BP01020M	4	IP67	M5 Male Right Angle	Pigtail	6.56 ft	2 m
BC-M8NA4BP01030M	4	IP67	M5 Male Right Angle	Pigtail	9.84 ft	3 m



+1 717.235.7512
techhelp@belf.com

belfuse.com/stewart-connector

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bel:](#)

[SS-12600-002](#) [BC-M5FA4BP01005M](#) [BC-M5FA4BP01020M](#) [BC-M5MA4BMA4010M](#) [BC-M5MA4BMA4030M](#) [BC-M5FA4BFA4020M](#) [BC-M5MA4BMA4005M](#) [BC-M5GA4BP01005M](#) [BC-M5FA4BP01010M](#) [BC-M5GA4BP01020M](#) [SS-12600-001](#) [SS-12600-003](#) [SS-12600-004](#) [BC-M5FA4BMA4010M](#) [BC-M5FA4BMA4020M](#) [BC-M5MA4BP01030M](#) [BC-M5FA4BMA4030M](#) [BC-M5FA4BP01030M](#) [BC-M5FA4BMA4005M](#) [BC-M5MA4BP01010M](#) [BC-M5FA4BFA4010M](#) [BC-M5FA4BFA4030M](#) [BC-M5MA4BP01005M](#) [BC-M5MA4BP01020M](#) [BC-M5NA4BP01030M](#) [BC-M5GA4BP01010M](#) [BC-M5FA4BFA4005M](#) [BC-M5MA4BMA4020M](#) [BC-M5NA4BP01010M](#) [BC-M5GA4BP01030M](#) [BC-M5NA4BP01005M](#) [BC-M5NA4BP01020M](#)