

# Stewart Connector

## M8 A-Code

### Connectors and Cable Assemblies

The M8 connectors and cables are particularly suitable for miniature sensors, applications with limited space, and many other applications that require reliable and robust compact sensors. This product line is IP68 rated when installed, adding to the reliable nature of these connectors in harsh environments.



#### Features & Benefits

- Water resistance IP68
- A-coding (or keying) within the M8 series prevents mismatching with other M8 coding/keying options
- RoHS Compliant

#### Applications


- Industrial
- Harsh Environments



## Connectors

Part Number	Gender	Performance	Orientation	Type	Termination
SS-12800-002	Male	IP68	Straight	Rear Panel Mount	Solder
SS-12800-003	Female	IP68	Straight	Rear Panel Mount	Solder Cup
SS-12800-004	Male	IP68	Right Angle	Rear Panel Mount	Solder

## Cable Assemblies

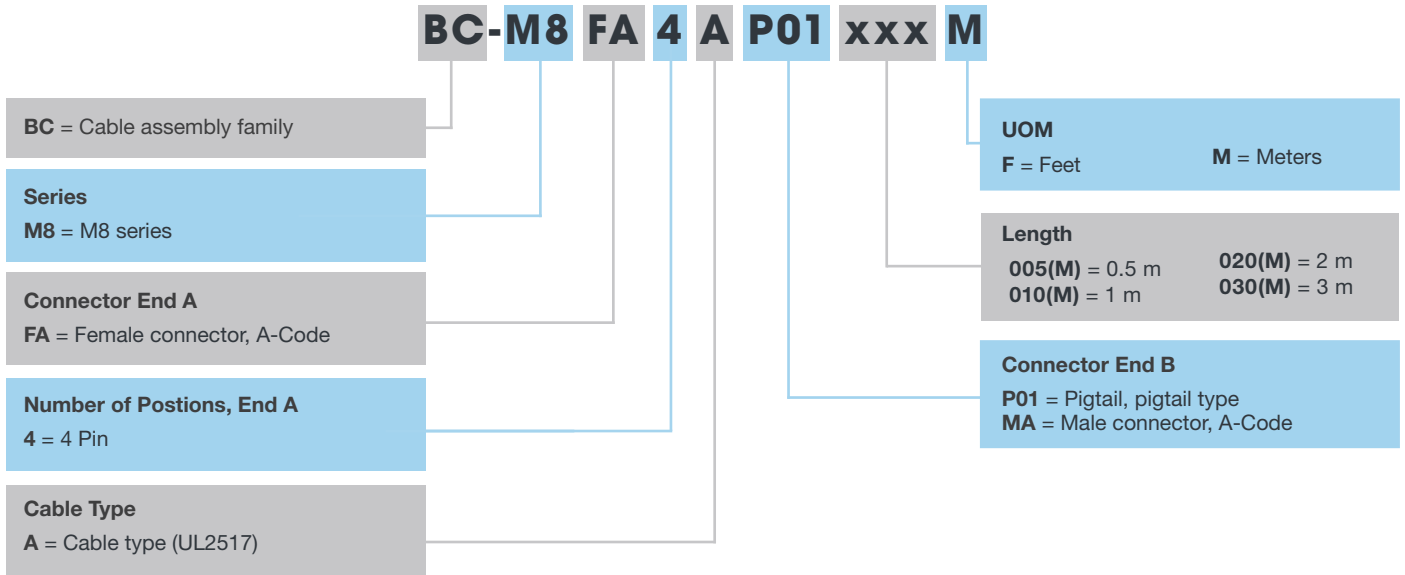

Part Number	Positions	Performance	Connector End A	Connector End B	Lengths Available	
					ft	m
BC-M8FA4AP01005M	4	IP68	M8 A-Code Female	Pigtail	1.64 ft	0.5 m
BC-M8FA4AP01010M	4	IP68	M8 A-Code Female	Pigtail	3.28 ft	1 m
BC-M8FA4AP01020M	4	IP68	M8 A-Code Female	Pigtail	6.56 ft	2 m
BC-M8FA4AP01030M	4	IP68	M8 A-Code Female	Pigtail	9.84 ft	3 m
BC-M8FA4AMA4005M	4	IP68	M8 A-Code Female	M8 A-Code Male	1.64 ft	0.5 m
BC-M8FA4AMA4010M	4	IP68	M8 A-Code Female	M8 A-Code Male	3.28 ft	1 m
BC-M8FA4AMA4020M	4	IP68	M8 A-Code Female	M8 A-Code Male	6.56 ft	2 m
BC-M8FA4AMA4030M	4	IP68	M8 A-Code Female	M8 A-Code Male	9.84 ft	3 m



+1 717.235.7512  
techhelp@belf.com

[belfuse.com/stewart-connector](http://belfuse.com/stewart-connector)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bel:](#)

[BC-M8FA4AP01030M](#) [BC-M8FA4AMA4010M](#) [BC-M8FA4AP01010M](#) [SS-12800-003](#) [SS-12800-002](#) [BC-](#)  
[M8FA4AMA4030M](#) [BC-M8FA4AMA4005M](#) [SS-12800-004](#) [BC-M8FA4AMA4020M](#) [BC-M8FA4AP01020M](#) [SS-12800-](#)  
[009](#)