

Specification Sheet

Part Number: T50L5M4

Engineered and manufactured for maximum performance and quality.


Made from 100% high-quality plastic to ensure efficient recycling.

Inside serration for a strong grip onto bundles.

Easy application either manually or with a tensioning tool.

Bent tail allows for simpler insertion.

Complies with MS3367-2-5, Class 1 and SAE-AS33671.

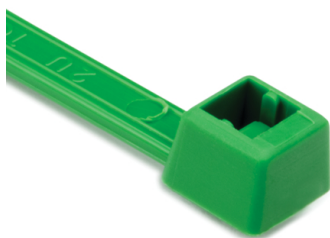

MilSpec Cable Tie, 15" Long, MS3367, UL Rated, 50lb Tensile Strength, PA66, Green, 1000/pkg

Article Number 111-00502

Type T50L

Color Green (GN)

Quantity Per bag

Product Description T-Series Cable Ties feature inside serrations to provide a positive hold on wire and cable bundles. The head design guarantees high tensile strength and a low insertion force. The bent tail design allows quick and simple installations by hand. For high-volume applications, tensioning tools are available to ensure consistent and safe installation. Specially manufactured to comply with Military Specification MS3367-2-5, Class 1 and SAE-AS33671.

Short Description	MilSpec Cable Tie, 15" Long, MS3367, UL Rated, 50lb Tensile Strength, PA66, Green, 1000/pkg
Global Part Name	T50L-PA66-GN
Minimum Tensile Strength (Imperial)	50
Minimum Tensile Strength (Metric)	225
Length L (Imperial)	15.0
Length L (Metric)	390.0
Identification Plate Position	none
Releasable Closure	No
Tie Closure	plastic pawl
Variant	Inside Serrated
Width W (Imperial)	0.19
Width W (Metric)	4.8
Bundle Diameter Min (Imperial)	0.06
Bundle Diameter Min (Metric)	1.5
Bundle Diameter Max (Imperial)	4.33
Bundle Diameter Max (Metric)	110.0

Thickness T (Metric)	1.4
Cable Tie Head Length (Imperial)	0.28
Cable Tie Head Width (Imperial)	0.32
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
US MIL SPEC	MS3367-2-5, Class 1 SAE-AS33671
Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Plenum Rating	AH-2
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	No
ROHS Compliant	Yes
Certification/Specification	UL 62275

UL Recognized (US) Yes

UL Listed (US and Canada) Yes

UL Recognized (US and Canada) Yes

UL Listed (US) Yes

Package Quantity (Imperial) 1000

Package Quantity (Metric) 1000

Customs Number 3926909988

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[T50L5M4](#)