


## Specification Sheet

Part Number: 150-09201

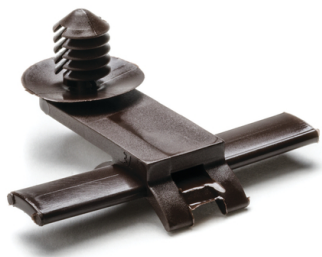

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Standoff Bundling Clip, 0.8" Long, 0.03 - 0.18" Panel Thickness, PA66, Brown, 500/pkg

Article Number 150-09201

Type COW20DP7

Color Brown (BN)

Quantity Per bag

Product Description Bundling clips are designed to provide simple and easy methods of securing cable bundles, hoses, or pipes. They are fastened onto the tape bar using tape or cable ties. The different fixing orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standard bundling clips are available as well as standoff and stud mount versions.

Short Description Standoff Bundling Clip, 0.8" Long, 0.03 - 0.18" Panel Thickness, PA66, Brown, 500/pkg

Global Part Name COW20DP7-PA66-BN

Length L (Imperial) 0.8

Length L (Metric) 42.0

Offset Length (Imperial) 0.79

Offset Length (Metric) 20.0

Fixation Method Fir Tree

Width W (Imperial) 1.7

Width W (Metric) 42.0

Height H (Imperial) 0.26

Height H (Metric) 6.6

Panel Thickness Min (Imperial) 0.03

Panel Thickness Max (Imperial) 0.18

Panel Thickness Min (Metric) 0.8

Panel Thickness Max (Metric) 4.5

Mounting Hole Diameter D (Imperial) 0.25 - 0.28

Mounting Hole Diameter D (Metric) 6.3 - 7.0 mm

Mounting Hole Diameter D Min (Imperial) 0.25

Mounting Hole Diameter D Max (Imperial) 0.28

Mounting Hole Diameter D Max (Metric) 7.0

Material Polyamide 6.6 (PA66)

Material Shortcut PA66

Flammability UL 94 V-2

UV Resistant (Yes/No) No

Operating Temperature -40°F to +185°F (-40°C to +85°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 500

Package Quantity (Metric) 500

Customs Number 3926909988

## About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 40 countries, with North American headquarters in Milwaukee, Wisconsin. ([www.hellermann.tyton.com](http://www.hellermann.tyton.com)).

© 2024 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[150-09201](#)