


Specification Sheet

Part Number: 151-02896

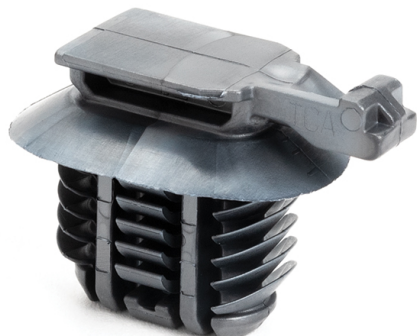

HellermannTyton connector clips provide a simple and easy method for mounting connectors to a mounting surface in a variety of applications. Detailed designs include anti-rattle disc features, anti-rotation oval fir trees, and clamps for mounting on edges.

HellermannTyton offers an assortment of connector clips that are available for a variety of connector slot designs found on most of the largest global connector manufacturers.

Conn. Clip w/Oval Fir Tree, 0.60 - 6.00 mm Panel Thickness, Oval Hole 9 X 17, PPS, Silver, 5000/ctn

Article Number 151-02896

Type CC11B

Color Silver (SR)

Quantity Per carton

Product Description Connector Clips feature various attachment point configurations to accommodate the many connectors on the market. They are first mated with a connector on a wire harness or cable assembly, then secured to a surface using the integrated mount. With so many configurations available, attachment surfaces can be a hole, edge, stud or even another harness assembly.

Short Description	Conn. Clip w/Oval Fir Tree, 0.60 - 6.00 mm Panel Thickness, Oval Hole 9 X 17, PPS, Silver, 5000/ctn
Global Part Name	CC11B-PPS-SR
Length L (Imperial)	1.18
Length L (Metric)	30.0
Fixation Method	Fir Tree
Width W (Imperial)	0.72
Width W (Metric)	18.20
Height H (Imperial)	0.81
Height H (Metric)	20.60
Panel Thickness Min (Metric)	0.6
Panel Thickness Max (Metric)	6.0
Mounting Hole Diameter D (Imperial)	0.7
Mounting Hole Diameter D (Metric)	9.0 x 17.0 mm
Material	Polyphenylene Sulfide (PPS)

Material Shortcut	PPS
Operating Temperature	-40°F to +302°F (-40°C to +150°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	5000
Package Quantity (Metric)	5000
Customs Number	3926909988

© 2022 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[151-02896](#)