

Specification Sheet


Part Number: 156-04005

Pre-assembled 2-piece self-affixing tie with coupler

Cable tie head can be moved after bundling

Easy addition of cables after assembly

For parallel routing of bundles that can be twisted 90° even after installation

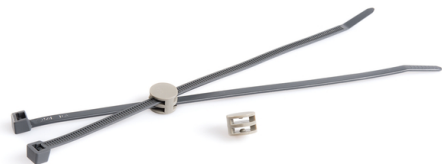

3-Pc T50R Tie with Coupler, 8" Long, 0.08" - 1.97" Dia, 50lbs, PA46, Gray, 500/bg

Article Number

156-04005

Type

T50RCOUPLER

Color

Gray (GY)

Quantity Per

bag

Product Description

The Coupler is the simple way to connect two cable ties for a parallel routing of two bundles. His special design allows the ties 90 degrees of rotation. This is ideal for all applications where the cable, pipe or hose should move flexible in relation to the fixing point. The Coupler can be used with one or two cable ties. This allows easily subsequent installation or replacements of further cables, pipes or hose.

Short Description

3-Pc T50R Tie with Coupler, 8" Long, 0.08" - 1.97" Dia, 50lbs, PA46, Gray, 500/bg

Global Part Name	T50RCOUPLER-PA46-GY
------------------	---------------------

Minimum Tensile Strength (Imperial)	50.0
-------------------------------------	------

Minimum Tensile Strength (Metric)	225
-----------------------------------	-----

Length L (Imperial)	7.874
---------------------	-------

Length L (Metric)	202.0
-------------------	-------

Identification Plate Position	none
-------------------------------	------

Tie Closure	plastic pawl
-------------	--------------

Variant	Inside Serrated
---------	-----------------

Width W (Imperial)	0.18
--------------------	------

Width W (Metric)	4.6
------------------	-----

Bundle Diameter Min (Imperial)	0.08
--------------------------------	------

Bundle Diameter Min (Metric)	2.0
------------------------------	-----

Bundle Diameter Max (Imperial)	1.97
--------------------------------	------

Bundle Diameter Max (Metric)	47.0
------------------------------	------

Bundle Diameter 1st Loop Max (Imperial)	1.97
---	------

Bundle Diameter 1st Loop Max (Metric)	50.0
---------------------------------------	------

Bundle Diameter 2nd Loop Max (Imperial)	1.97
Bundle Diameter 2nd Loop Max (Metric)	50.0
Height H (Imperial)	0.33
Height H (Metric)	8.3
Cable Tie Width Max (Imperial)	0.185
Cable Tie Width Max (Metric)	4.70
Material	Polyamide 4.6 (PA46)
Material Shortcut	PA46
Material Cable Tie	Polyamide 4.6 (PA46)
Flammability	UL 94 V-2
UV Resistant (Yes/No)	No
Operating Temperature	-40°F to +266°F (-40°C to +130°C)
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500

About HellermannTyton

HellermannTyton is a global manufacturer of cable management and identification solutions for automotive, solar, electrical, construction, industrial automation, broadband and other OEM markets. The company's integrated approach to product design, sustainability, production, quality assurance and delivery is optimized to benefit local and global customers. HellermannTyton operates in 39 countries, with North American headquarters in Milwaukee, Wisconsin. (www.hellermann.tyton.com).

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[156-04005](#)