


## Specification Sheet

Part Number: TFOT-1

Markers are pre-coiled so that they can be snapped into place over the cable without the use of adhesives.

Non-adhesive design means that the markers can be installed at any temperature or over dirty or oily surfaces.

Pre-printed text is protected by a thick layer of clear acrylic which provides UV protection and abrasion resistance.

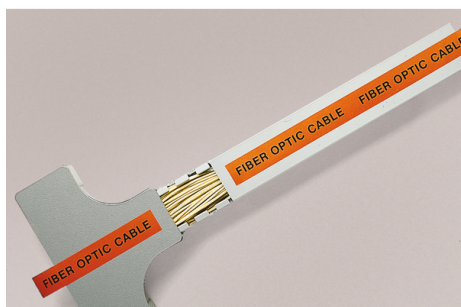

Fiber Optic Cable Marker Tape, 1.0" x 54', VL, Orange, 1/roll

**Article Number** 597-00044

**Type** TFOT1

**Color** Orange (OG)

**Quantity Per** pack

**Product Description** Designed to be used on the Lightguide Fiber Optic Protection System to identify the routing of fiber optic cable. It is a 1" wide range vinyl with black lettering that states, "FIBER OPTIC CABLE." The legend is repeated every six inches.

**Short Description** Fiber Optic Cable Marker Tape, 1.0" x 54', VL, Orange, 1/roll

**Global Part Name** TFOT1-V-OG

<b>Length L (Imperial)</b>	54
<b>Length L (Metric)</b>	16.46
<b>Width W (Imperial)</b>	1.0
<b>Width W (Metric)</b>	25.4
<b>Height H (Imperial)</b>	2.2
<b>Height H (Metric)</b>	50.8
<b>Material</b>	Vinyl (V)
<b>Material Shortcut</b>	V
<b>Halogen Free</b>	No
<b>Operating Temperature</b>	-18°F to +200°F (-29°C to +93°C)
<b>Reach Compliant (Article 33)</b>	No
<b>ROHS Compliant</b>	Yes
<b>Package Quantity (Imperial)</b>	1

<b>Package Quantity (Metric)</b>	1
<b>Customs Number</b>	3919905060
<b>Weight (Metric)</b>	0.453
<b>Weight (Imperial)</b>	.2

© 2022 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[TFOT-1](#)