


Specification Sheet

Part Number: FALCX9OM43

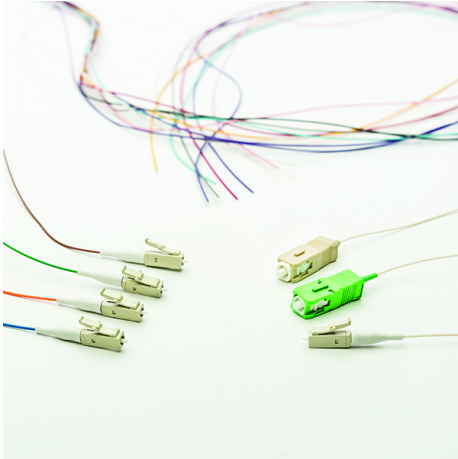

Assembly with optical connector on only one end.
Factory terminated and tested.

Ideal for fusion splicing within FTTx applications.

Pigtail, LC 900um, MM OM4, 1m, 1/pkg

Article Number	904-01181
Type	FALCX9OM43
Color	White (WH)
Quantity Per	EA
Product Description	Optical Fiber Pigtails are used in place of field terminations to provide a reliable and high-performing pluggable connection for outdoor and higher fiber count feeder and trunk cables. The factory terminated and tested pigtailed can be attached by fusion splice to provide a pluggable interface for the bulk optical cable or to create a discreet fiber breakout within an enclosure.
Short Description	Pigtail, LC 900um, MM OM4, 1m, 1/pkg

Global Part Name FALCX9OM43-DIV-WH

Contents of pkg/kit 1m Pigtail

Length L (Imperial) 3

Length L (Metric) 1

Variant Optical Pigtail

Material Various (DIV)

Material Shortcut DIV

Package Quantity (Imperial) 1

Package Quantity (Metric) 1

Customs Number 8544700000

Weight (Metric) .006

Weight (Imperial) .013

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HellermannTyton:](#)

[FALCX9OM43](#)