


NO.	MASSE / DIMENSION
D1	35.4
D2	23.9
D	15.9
E	0.23
G	35
K	3.89
L1	47
L2	15.9

NO.	BESCHREIBUNG / DESCRIPTION
2	ISOLIERKÖRPER BUCHSE / INSULATOR SOCKET
4	DICKTKÖRPER / GROMMET
5	ENDRING / ENDRING
7	KONTAKT BUCHSE / CONTACT SOCKET
8	GEHÄUSE / RECEPTACLE
9	ENDGEHÄUSE / ENDBELL
12	ÜBERWURFMUTTER / COUPLING NUT
14	WELLFEDER / WASHER
15	KABELTÜLLE / BUSHING
16	KABELKLEMME / CABLE CLAMP
20	ZYLINDER-SCHRAUBE / CYLINDER HEAD SCREW

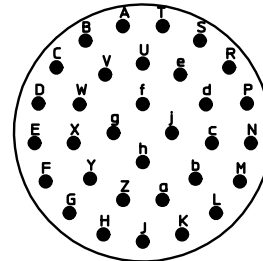

Note: Due to an automatic nomenclature system, numbers generated may not be sequential.
 Notiz: Durch ein automatisches Benennungssystem können Nummerierungen entstehen, die nicht fortlaufend sind.

Material Specification:	
Shell Material:	ALUMINIUM ALLOY
Shell Plating:	OLIVE DRAB CHROMATE OVER CADMIUM PLATING
Insulator Material:	POLYCHLOROPRENE
Contact Material:	COPPER ALLOY, GOLD PLATED
Contact Plating:	COPPER ALLOY, GOLD PLATED

all dimensions are in mm
 Dimensions without tolerance indications are general tolerances in acc. with DIN7168m

drawing for
 CUSTOMER

 ITT Industries <small>ITTCANNON GmbH D - 71384 Weinstadt/Germany</small>	description	MS3116F1832S
	STRAIGHT PLUG GROMMET SEAL WITH STRAIN RELIEF SOLDER CUP / SOCKET / Layout: 1832	

© All rights reserved. Reproduction or issue to third in any form whatever is only permitted with written authorization of ITT Cannon



page 1/1
 revision 42.7

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Sensata:](#)

[MS3116F18-32S](#)