



Part Number:	IE260412-1	DRAWN CJ	10/12/2017
		CHECKED P.D.	11/2/2017
	Description: Electro-Mechanical Indicator	APPROVED C.E.	11/2/2017
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at <a href="http://www.dbunlimitedco.com">www.dbunlimitedco.com</a>			


Top View

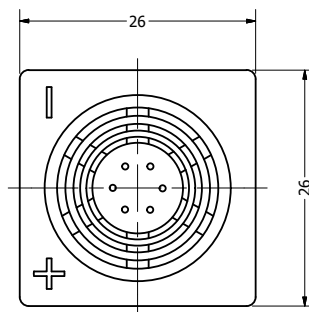

Side View

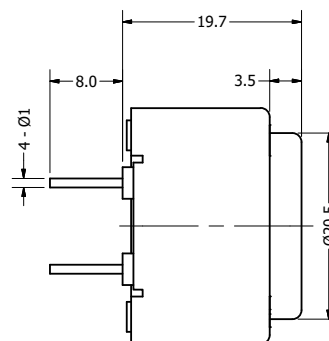

Bottom View

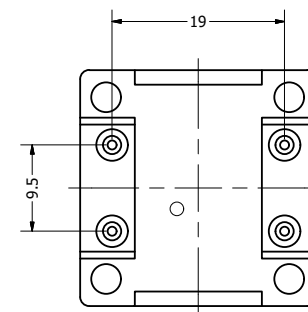

Items	Specifications	Conditions				
Min. Sound Pressure Level	95	dB (@ 10cm)				
Tone	Single					
Resonant Frequency	400 ± 100	Hz				
Rated Voltage	12	V	REV	DESCRIPTION	DATE	APPROVED
Voltage Range	8 ~ 16	V		Released from Engineering	10/21/2013	J.S.
Max. Rated Current	50	mA	1	Update temperature, drawing to new template	11/2/2017	C.E.
Storage Temperature	-40 ~ +85	°C				
Operating Temperature	-30 ~ +70	°C				
Connection Method	PC Pins					
Mount Type	Thru Hole					
Housing Material	ABS					
Weight	17	g				

REVISION HISTORY

NOTES

- 1) All dimensions are in mm unless otherwise noted
- 2) All tolerances are ± 0.5 mm unless otherwise noted
- 3) All parts meet RoHS
- 4) Subject to change or redrawn without notice

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE260412-1](#)