




TOP VIEW

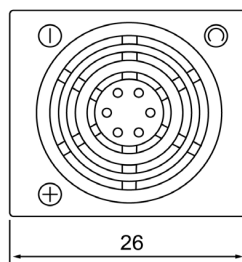

SIDE VIEW

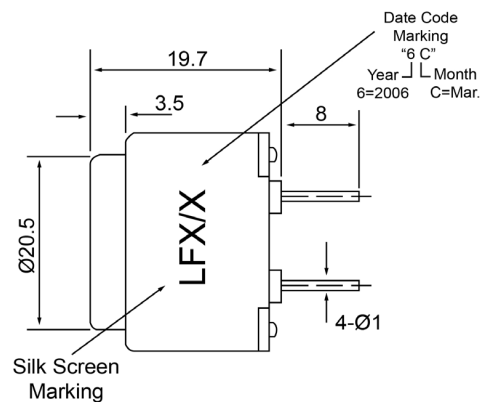

BOTTOM VIEW

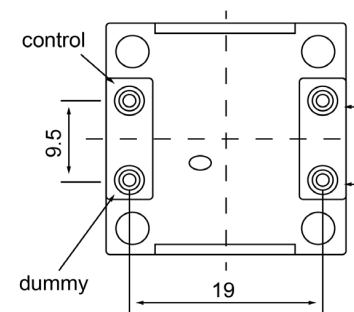

Specifications			Notes	Revision History											
Description	Value	Unit		Version	Description		Date		Approved						
Technology	Electro-Mechanical		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013		J.S						
Resonant Frequency	400	(Hz)													
Rated Voltage	24	(V)													
SPL @ 10cm	95	(dBA)													
Tone	Single Tone														
Mount Type	Thru Hole														
Voltage Range	20 ~ 28	(V)													
Max Rated Current	50	(mA)													
Housing Material	ABS														
Operating Temperature	-20 ~ +60	°C													
Storage Temperature	-30 ~ +70	°C	 DB UNLIMITED	Drawn by		Date		Checked by		Date		Approved by		Date	
Weight	17	(g)		A.B.		10/21/2013		C.E.		10/21/2013		J.S		10/21/2013	
			Electro-Mechanical Indicator			IE260424-1									

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[IE260424-1](#)