




TOP VIEW

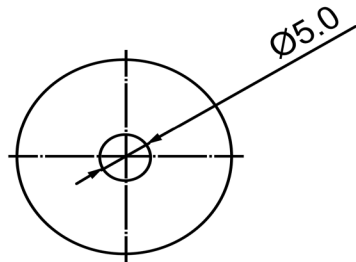

SIDE VIEW

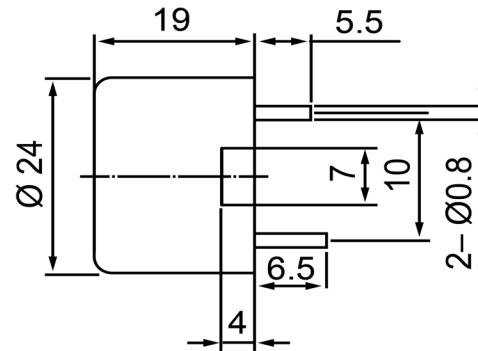

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description	Date	Approved		
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS 	1	Released from Engineering	10/21/2013	J.S		
Resonant Frequency	3,450	(Hz)							
Rated Voltage	8	(V)							
SPL @ 10cm	90	(dBA)							
Capacitance	20,000	(pF)							
Mount Type	Thru Hole								
Voltage Range	2 ~ 30	(V)							
Max Rated Current	5	(mA)							
Housing Material	ABS777								
Operating Temperature	-20 ~ +60	°C							
Storage Temperature	-30 ~ +70	°C							
Weight	5	(g)							
				Piezo Transducer		TP243408-1			
				Drawn by	Date	Checked by	Date	Approved by	Date
				A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP243408-1](#)