

DX 10

Art. No. 4610 – 4 Ω



Technische Daten / Technical Data

Nennbelastbarkeit	50 W
Rated power	
Impedanz	4 Ω
Impedance	
Übertragungsbereich (–10 dB)	80–20000 Hz
Frequency response (–10 dB)	
Mittlerer Schalldruckpegel	88 dB (1 W/1 m)
Mean sound pressure level	
Grenzauslenkung x_{mech}	± 3 mm
Excursion limit x_{mech}	
Resonanzfrequenz	110 Hz
Resonant frequency	
Obere Polplattenhöhe	4 mm
Height of front pole-plate	
Schwingspulendurchmesser	25 mm Ø / 14 mm Ø
Voice coil diameter	
Wickelhöhe	6 mm
Height of winding	
Schallwandöffnung	91 mm Ø
Cut-out diameter	
Anschluss	
Terminal	4,8 x 0,8 mm (+) / 2,8 x 0,8 mm (–)
Gewicht netto	0,64 kg
Net weight	

10 cm (4") 2-Wege-Koaxiallautsprecher mit Polypropylenmembran und Polycarbonat-Hochtöner. Integrierte Frequenzweiche (Kondensator) für den Hochtöner. Ausgewogener Klang. Unproblematische Montage in Fahrzeugen mit 10-cm-Einbauöffnungen. Mit Montagering und Gitter Einbau auf Türverkleidungen und Heckablagen möglich. Paarweise verpackt.


Anwendungsmöglichkeiten: Fahrzeuge, Reisemobile

Zubehör: Inklusive Montagematerial und Gitter.



10 cm (4") 2-way coaxial loudspeakers with 10 cm polypropylene cone and polycarbonate dome tweeter. Integrated crossover (capacitor) for the tweeter. Very balanced sound. Straightforward installation in vehicles with 10 cm cutouts. Door and rear tray installation possible using mounting ring and grille. Packed in pairs.

Typical applications: Vehicles, Mobile homes

Accessories: Mounting accessories and grilles are included.

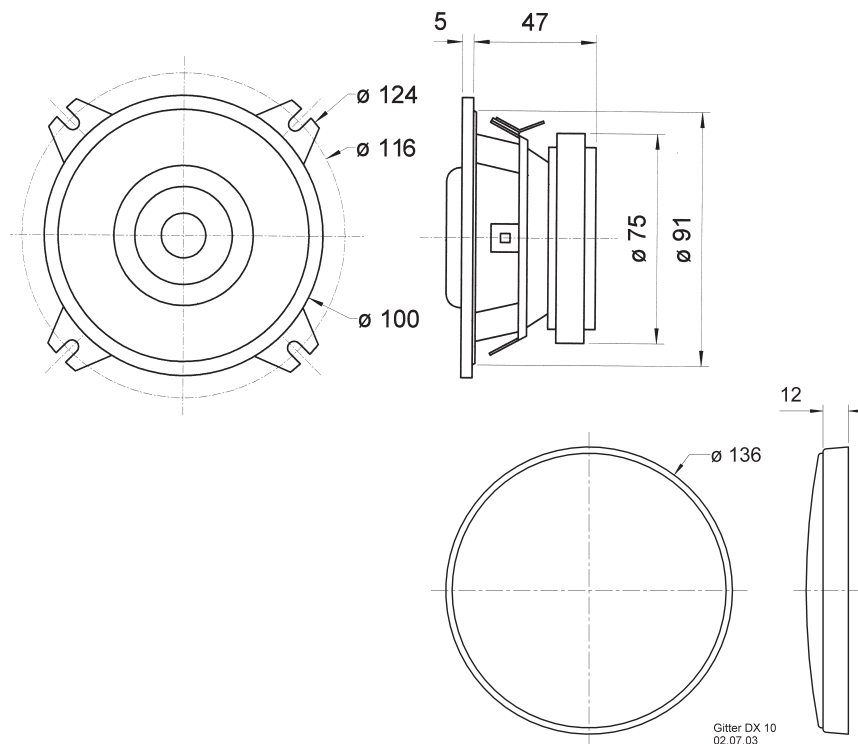

DX 10 - 4 Ohm

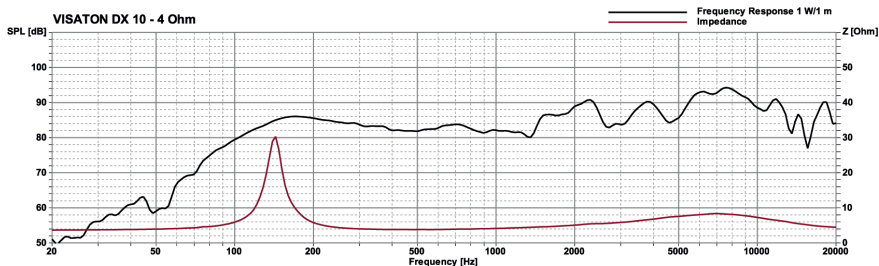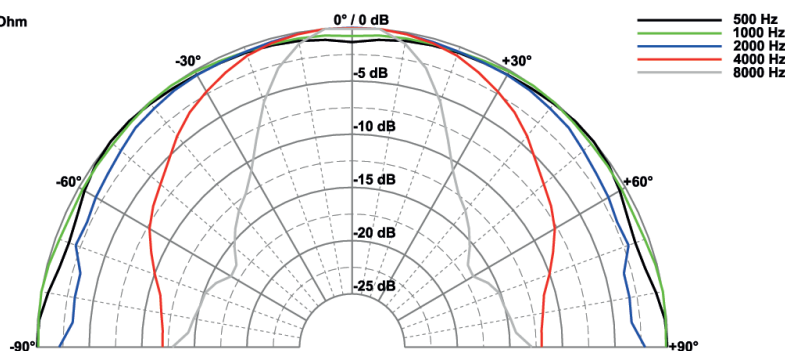

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Visaton:](#)

[4610](#)