

SC 5.9 OM

Art. No. 8002 – 4 Ω

Art. No. 8003 – 8 Ω




Technische Daten / Technical Data


Nennbelastbarkeit	
Rated power	10 W
Impedanz	
Impedance	4 Ω / 8 Ω
Übertragungsbereich (–10 dB)	
Frequency response (–10 dB)	90–20000 Hz
Mittlerer Schalldruckpegel	
Mean sound pressure level	84 dB (1 W/1 m)
Resonanzfrequenz	
Resonant frequency	170 Hz
Obere Polplattenhöhe	
Height of front pole-plate	3 mm
Schwingspulendurchmesser	
Voice coil diameter	14 mm Ø
Wickelhöhe	
Height of winding	4 mm
Schallwandöffnung	
Cut-out diameter	43 x 82 mm (oval)
Anschluss	
Terminal	4,8 x 0,8 mm (+)/2,8 x 0,8 mm (–)
Gewicht netto	
Net weight	0,14 kg

5 x 9 cm (2" x 3,5") Breitbandlautsprecher mit kräftigem Antrieb, gutem Wirkungsgrad und einem sehr ausgeglichenen Frequenzgang. Durch die sehr gute Hochtonwiedergabe und die geringen Abmessungen eignet sich der SC 5.9 OM besonders für platz sparende Lösungen im Bereich Multimedia und Dolby Surround sowie als Ersatzbestückung für Flachbildfernseher.


5 x 9 cm (2" x 3.5") full-range driver with a powerful magnetic drive, good efficiency and a very balanced frequency response. Due to the very good highrange reproduction and the small size any non-spacious application in the field of multimedia and Dolby Surround are possible. The SC 5.9 OM can furthermore be used as replacement part for internal flat TV speakers.

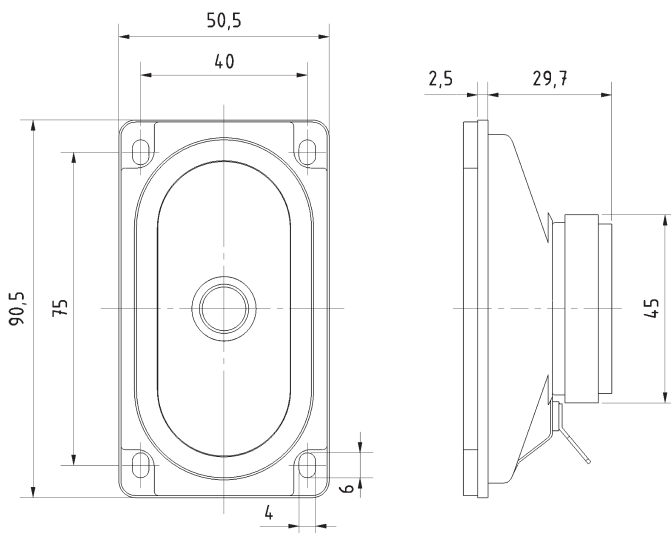


SC 5.9 OM - 8 Ohm (A°)

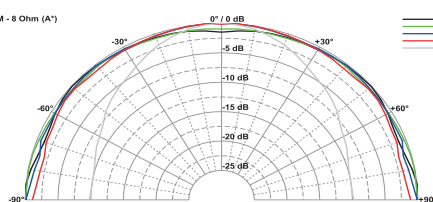


SC 5.9 OM - 8 Ohm (B°)

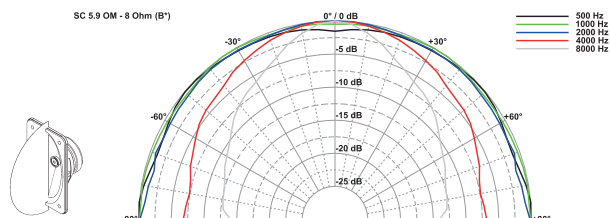

VISATON SC 5.9 OM - 4 Ohm

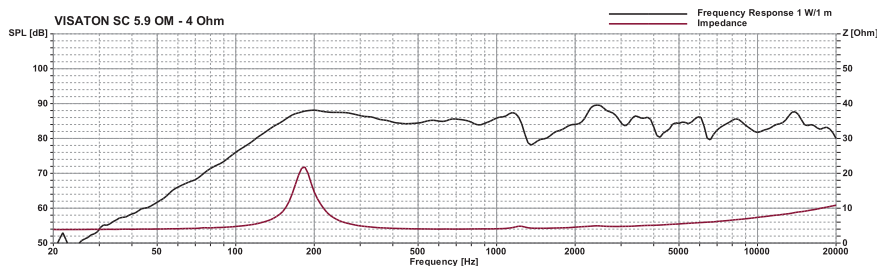

VISATON SC 5.9 OM - 8 Ohm

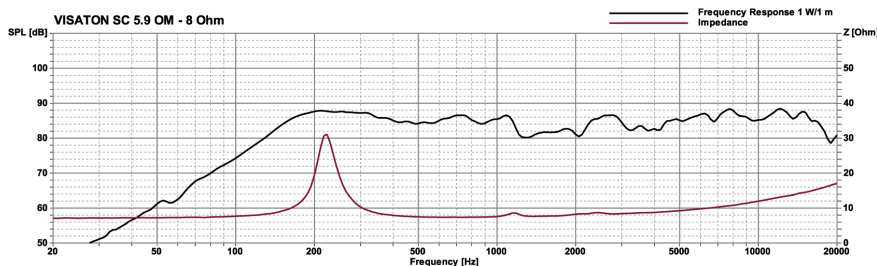

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Visaton:](#)

[8003](#)