

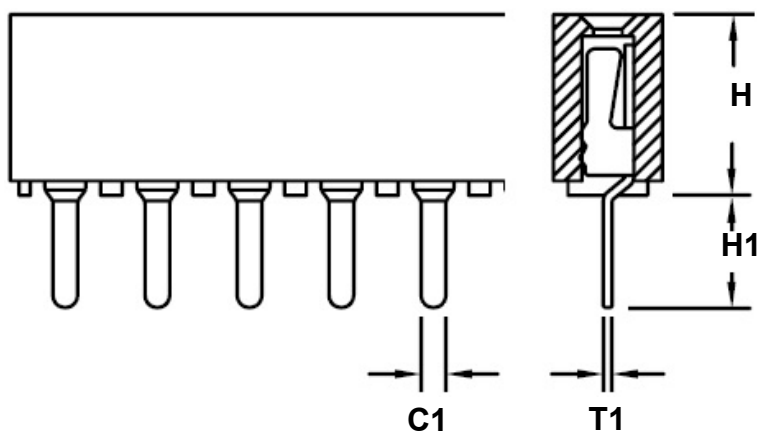


0.1" 40 pin Vertical Female Header Through Hole Gold

REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
C		1.02				
C1		0.68				
E		2.54			0.100	
H		8.50				
H1		3.10				
L1		99.06			3.900	
L2		101.6			4.000	
T1		0.40				
W2		2.54				

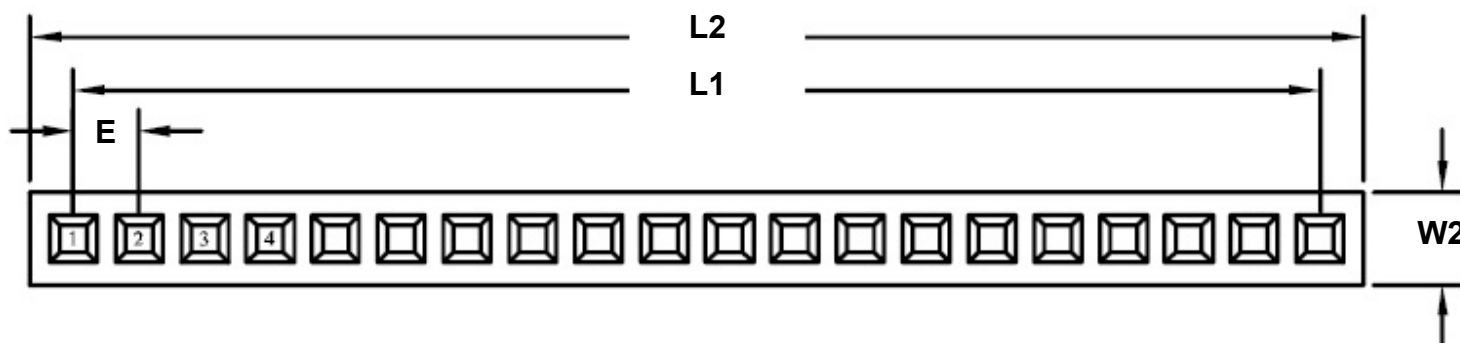

Recommended PCB Hole Layout

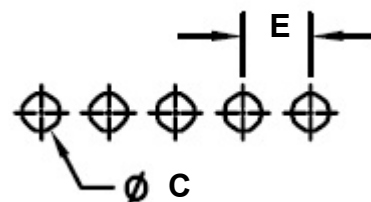

SPECIFICATIONS

Plastic body construction: PA6T plastic (320°C melting point)

Pin construction: Gold plated (brass pin, with 1um gold over 50um nickel)

Operating temperature range: -40°C to +130°C

Reflow maximum temperature: +260°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Chip Quik:](#)

[HDR100IMP40F-G-V-TH](#)