


iUCOM-2D

USB Module supports two RS-232/422/485 Port, RoHs

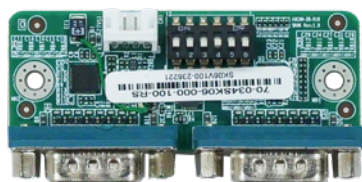

Packing List

1 x iUCOM-2D peripheral board	1 x USB Cable (P=2.0)
1 x USB Cable (P=2.54)	1 x QIG

Ordering Information

Part No.	Description
iUCOM-2D-R10	USB Module supports two RS-232/422/485 Port(DB9), RoHs

Features

- Two-port RS-232/422/485 (DB-9)
- 1024 bytes transmit/ 512 bytes receive FIFO
- High-speed 16C550/16C650/16C750/16C850 compatible UARTs
- Baud rate supports 115.2K, max. up to 6M

Specifications

Model Name	iUCOM-2D
Form Factor	USB2.0 (1*4pin, P=2.0)
USB Bridge to Quad Serial Port	WCH CH342
Buffer/Transceiver Series	F81435
IO	2 x RS-232/422/485 (DB-9)
Operating Temperature	0°C ~ 60°C
Operating Humidity	10% ~ 95%, non-condensing
Dimensions (LxW)	65mm x 35mm

iUCOM-4R4P

USB Module supports eight-Port RS-232/422/485, RoHs



Packing List

1 x iUCOM-4R4P peripheral board	1 x USB Cable (P=2.0)
1 x USB Cable (P=2.54)	1 x QIG

Ordering Information

Part No.	Description
iUCOM-4R4P-R10	USB Module supports eight-Port RS-232/422/485 (four DB9 and four RJ45), RoHs
32205-002700-200-RS	RS-232/422/485 cable, 200 mm, 2*5pin, p=2.0 mm

Features


- Eight-port RS-232/422/485
- 1024 bytes transmit/ 512 bytes receive FIFO
- High-speed 16C550/16C650/16C750/16C850 compatible UARTs
- Baud rate supports 115.2K, max. up to 6M

Specifications

Model Name	iUCOM-4R4P
Form Factor	USB2.0 (1*4pin) Reserved 5V power connector (1*2 pin)
USB Bridge to Quad Serial Port	WCH 348
Buffer/Transceiver Series	F81435
IO	4 x RS-232/422/485 (RJ-45) 4 x RS-232/422/485 (2x5pin, P=2.0)
Operating Temperature	0°C ~ 60°C
Operating Humidity	10% ~ 95%, non-condensing
Dimensions (LxW)	105mm x 55mm

iUCOM-8D

USB Module supports eight-Port RS-232/422/485, RoHs

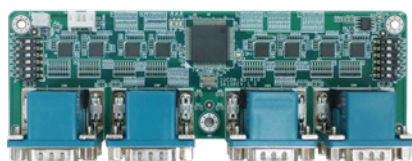

Packing List

1 x iUCOM-8D peripheral board	1 x USB Cable (P=2.0)
1 x USB Cable (P=2.54)	1 x QIG

Ordering Information

Part No.	Description
iUCOM-8D-R10	USB Module supports eight RS-232/422/485 Port (DB9), RoHs

Features


- Eight-port RS-232/422/485
- 1024 bytes transmit/ 512 bytes receive FIFO
- High-speed 16C550/16C650/16C750/16C850 compatible UARTs
- Baud rate supports 115.2K, max. up to 6M

Specifications

Model Name	iUCOM-8D
Form Factor	USB2.0 (1*4pin) Reserved 5V power connector (1*2 pin)
USB Bridge to Quad Serial Port	WCH 348
Buffer/Transceiver Series	F81435
IO	8 x RS-232/422/485 (DB9)
Operating Temperature	0°C ~ 60°C
Operating Humidity	10% ~ 95%, non-condensing
Dimensions (LxW)	150mm x 55mm

iUCOM-4D

USB Module supports Quad RS-232/422/485 DB-9 Port, RoHs

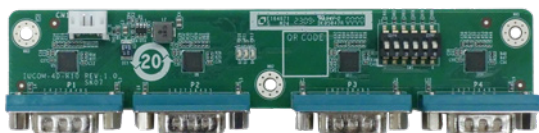

Specifications

Model Name	iUCOM-4D
Form Factor	USB2.0 (1*4pin, P=2.0)
USB Bridge to Quad Serial Port	WCH CH344
Buffer/Transceiver Series	Fintek 81435
IO	4 x RS-232/422/485 (DB-9)
Operating Temperature	0°C ~ 60°C
Operating Humidity	10% ~ 95%, non-condensing
Dimensions (LxW)	140mm x 35mm

Packing List

1 x iUCOM-4D peripheral board	1 x USB Cable (P=2.0)
1 x USB Cable (P=2.54)	1 x QIG


Ordering Information

Part No.	Description
iUCOM-4D-R10	USB Module supports four RS-232/422/485 Port(DB-9), RoHs

Features

- Quad-port RS-232/422/485
- 1024 bytes transmit/ 512 bytes receive FIFO
- High-speed 16C550/16C650/16C750/16C850 compatible UARTs
- Baud rate supports 115.2K, max. up to 6M

Dimensions (mm)

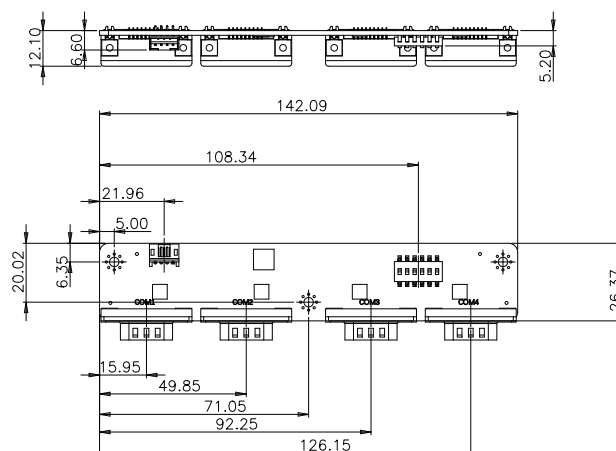

iUCOM-4R

USB Module supports Quad RS-232/422/485 RJ-45 Port, RoHs



Specifications

Model Name	iUCOM-4R
Form Factor	USB2.0 (1*4pin, P=2.0)
USB Bridge to Quad Serial Port	WCH CH344
Buffer/Transceiver Series	Fintek 81435
IO	4 x RS-232/422/485 (RJ-45)
Operating Temperature	0°C ~ 60°C
Operating Humidity	10% ~ 95%, non-condensing
Dimensions (LxW)	95mm x 40mm

Packing List

1 x iUCOM-4R peripheral board	1 x USB Cable (P=2.0)
1 x USB Cable (P=2.54)	1 x QIG


Ordering Information

Part No.	Description
iUCOM-4R-R10	USB Module supports Quad RS-232/422/485 Port (RJ45), RoHs

Features

- Quad-port RS-232/422/485
- 1024 bytes transmit/ 512 bytes receive FIFO
- High-speed 16C550/16C650/16C750/16C850 compatible UARTs
- Baud rate supports 115.2K, max. up to 6M"

Dimensions (mm)

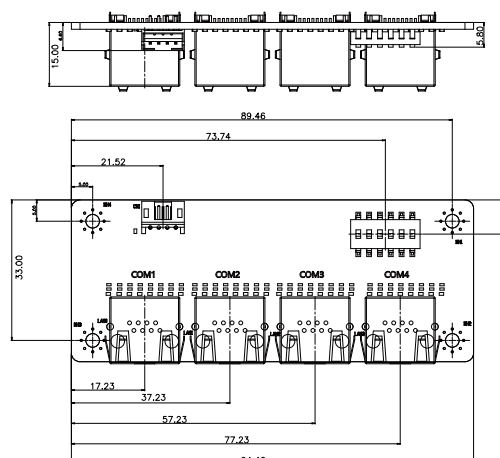

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[IEI:](#)

[iUCOM-2D-R10](#)