



MECHANICALS


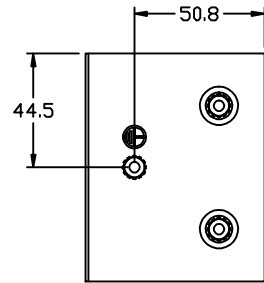


STUD, M5, 4x

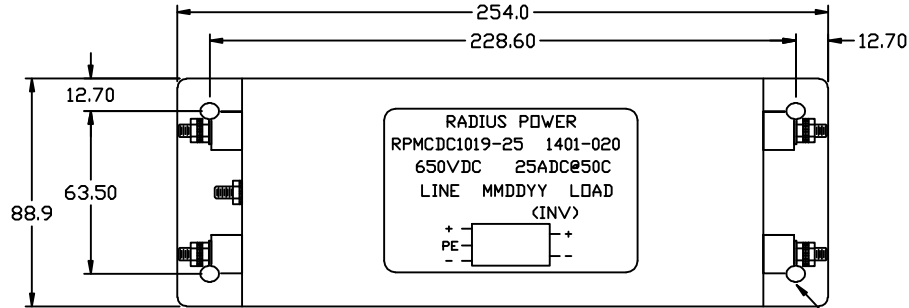

SLOT 7.6x6.4, 4x

STUD, GND, M5
EXT. WASHER/NUT

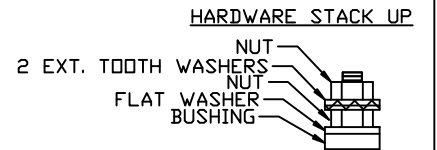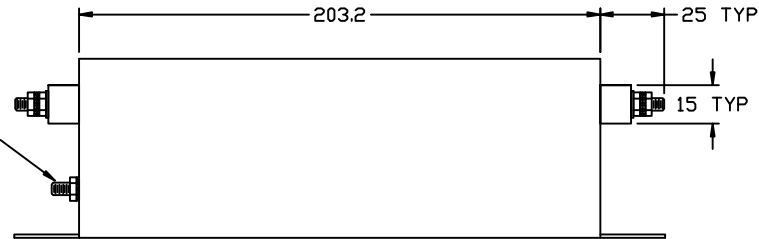

MODEL / ITEM	RPMCDC1019-25 / 1401-020	
UNITS	MM	
DATE	082313	
HOUSING	CRS / NICKEL OR TIN	
VOLT / CURR	650VDC / 25ADC	
FREQ(HZ)		
AMB / STORAGE	50C / -40 TO 100C	
WT(LB/KG), TYP	5.1/2.3	
HIPOT, LG (VDC)	3.5K	
TYP LK CURR		AN AstrodyneTDI COMPANY
TOLERANCE	0.0/0.00=±0.5/±0.25	CONFIDENTIAL DOCUMENT
ANGLE=±0.5°		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Astrodyne TDI:](#)

[RPMCDC1019-25](#)