

# CMOS COLOR CAMERA MODULE

## DCM320PT

### Features


TOTAL PIXELPLUS CMOS COLOR CAMERA

CMOS PC1058

Input voltable DC6V-26V


0.1Lux at F1.2

VIDEO DOOR PHONE, TOY, INDUSTRIAL USE AND SO ON

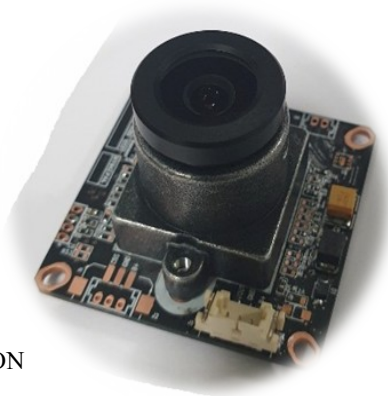

### Specifications

Model	DCM320PT
IMAGE DEVICE	PC1058(1/3")
Effective Pixels	976(H) x 592(V)
RESOLUTION	800TV lines
Scanning system	2 :1 interlace
VIDEO OUTPUT	1.0Vp_p
Synchronization	Internal
MIN ILLUMINATION	More than 45dB
Backlight Compensation	BLC ON/OFF
White Balance	Auto
Auto Gain Control	Auto
Day & Night	IR OPTION : Cds ON/Off
Mirror	ON/OFF
Lens	STD. 650nm FILTER + 3.6mm 92' LENS or available
POWER CONSUMPTION	DC6V-26V , DC12V 60mA
OPERATING TEMPERATURE	-10°C~+50°C , RH 95% MAX
STORAGE TEMPERATURE	-20°C~+60°C , RH 95% MAX
DIMENSIONS	32X32x1.2T

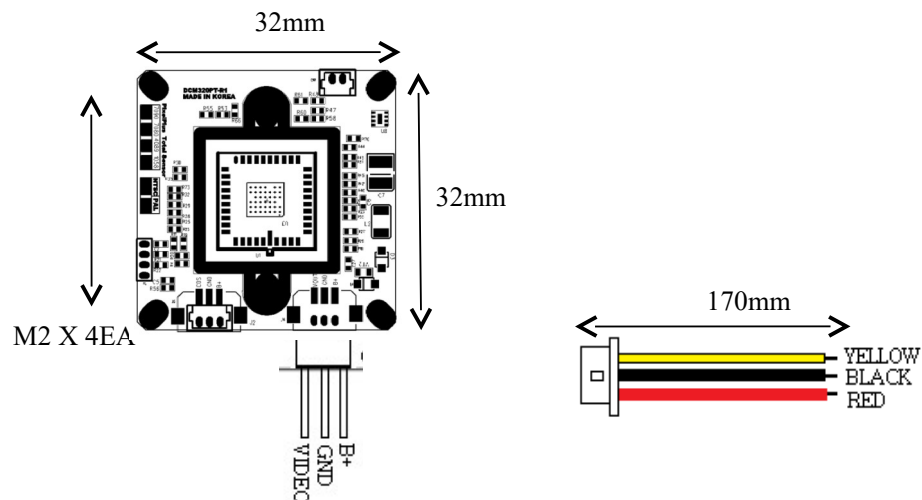

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SparkFun Electronics:](#)

[SEN-15906](#)