

## PC01\_LCUS\_LCUS\_SM20E\_XX.X\_BBx\_ETC

### Description

Simplex patch cord, LC classic to LC classic, UPC, simplex 2.0mm\_XX.X\_yellow, SM G.652.D coming\_ALTICE



Features	Features
- Push-pull mechanism for best handling and high packing density	
- One-piece design for easy termination	
- Short rigid length	
- Switchable duplex connectors	

### Technical Data

#### General Data

Description	Values
General Typ	Simplex LC patch cord
Operation temperature	-25 up to 70°C
UL Rating	UL 94 V-0
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes

#### Connector left

Description	Values
Connector typ	LC simplex Classic
Polish	UPC
Color Housing	Blue
Color Clip	Blue
Color Boot	Blue
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	B
Insertion loss 97% dB / mean dB	0.45 / 0.2
Return Loss	50
Durability	1000
Tensile load	100 N
Tensile load acc. To GR-326-COR	Fullfilled

#### Connector right

Description	Values
Connector typ	LC simplex Classic
Polish	UPC
Color Housing	Blue
Color Clip	Blue
Color Boot	Blue
Design connector acc. To	IEC 61754-20, TIA 604-10-A
Performance class H+S	B
Insertion loss 97% dB / mean dB	0.45 / 0.2
Return Loss	50
Durability	1000
Tensile load	100 N

## PC01\_LCUS\_LCUS\_SM20E\_XX.X\_BBx\_ETC


Tensile load acc. To GR-326-COR

Fulfilled

### Cable

Description	Values
Cable typ	Simplex Cable
Fiber count	1
Fiber	1 x 0.9 mm
Fiber typ	E9/125-SM ultra G.652.D / G.657.A1
Outer diameter	2 mm

### Technical Drawing

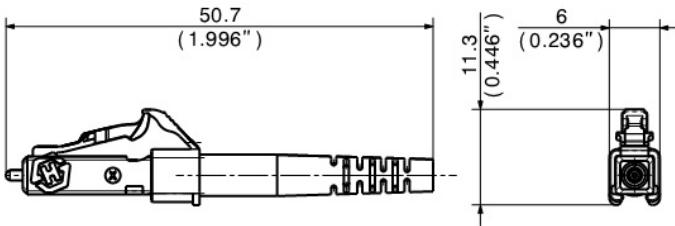

### Ordering information

Meter (m)	Item number	Description
2	85140012	PC01_LCUS_LCUS_SM20E_02.0_BBx
3	85140013	PC01_LCUS_LCUS_SM20E_03.0_BBx
5	85140014	PC01_LCUS_LCUS_SM20E_05.0_BBx
7	85140015	PC01_LCUS_LCUS_SM20E_07.0_BBx
10	85140016	PC01_LCUS_LCUS_SM20E_10.0_BBx
15	85140017	PC01_LCUS_LCUS_SM20E_15.0_BBx
20	85140018	PC01_LCUS_LCUS_SM20E_20.0_BBx
25	85140019	PC01_LCUS_LCUS_SM20E_25.0_BBx
30	85140020	PC01_LCUS_LCUS_SM20E_30.0_BBx

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[FLC-Z/K-A007\\_100-P](#)