

## PT01\_SCAS\_0000\_SM09E\_XX.X\_S0

### Description

Single pigtail, SC-HQ BTW, APC, fiber 0.9mm\_XX.X\_yellow, SM G.652.D



Features	Features
- Push-pull connector	
- One-piece design for easy and quick termination	
- High mechanical and thermal resistance according to Telcordia GR-326-CORE	

### Technical Data

#### General Data

Description	Values
General Typ	SC pigtail
Operation temperature	-40 up to 85°C
RoHS compliant 2001/65/EU	Yes
REACH compliant	Yes

#### Connector left


Description	Values
Connector typ	SC pigtail
Polish	APC
Color Housing	Black
Color Boot	Green
Design connector acc. To	IEC 61754-4, TIA 604-3
Performance class H+S	S
Insertion loss 97% dB / mean dB	0.25 / 0.12
Return Loss	65
Durability	1000
Performance class H+S	0

#### Cable

Description	Values
Cable typ	Semi-tight Tube
Fiber count	1
Fiber	1 x 0.9 mm
Fiber typ	E9/125-SM ultra G.652.D / G.657.A1

PT01\_SCAS\_0000\_SM09E\_XX.X\_S0

## Technical Drawing

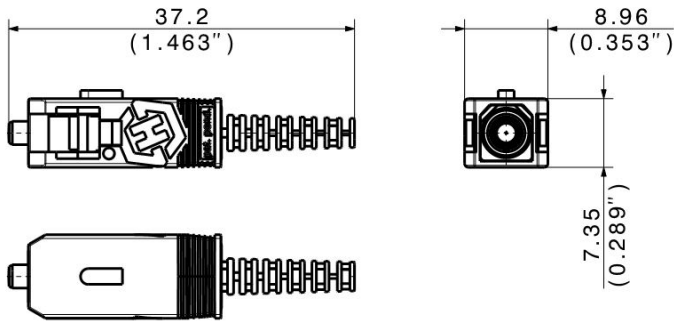

## Ordering information

Meter (m)	Item number	Description
2	85004547	PT01_SCAS_0000_SM09E_02.0_S0

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HUBER+SUHNER:](#)

[PT01\\_SCAS\\_0000\\_SM09E\\_02.0\\_S0](#)