


## Triple Flat-Panel Rail Wall Mount for 10" to 15" TVs and Monitors

MODEL NUMBER: **DMR1015X3**

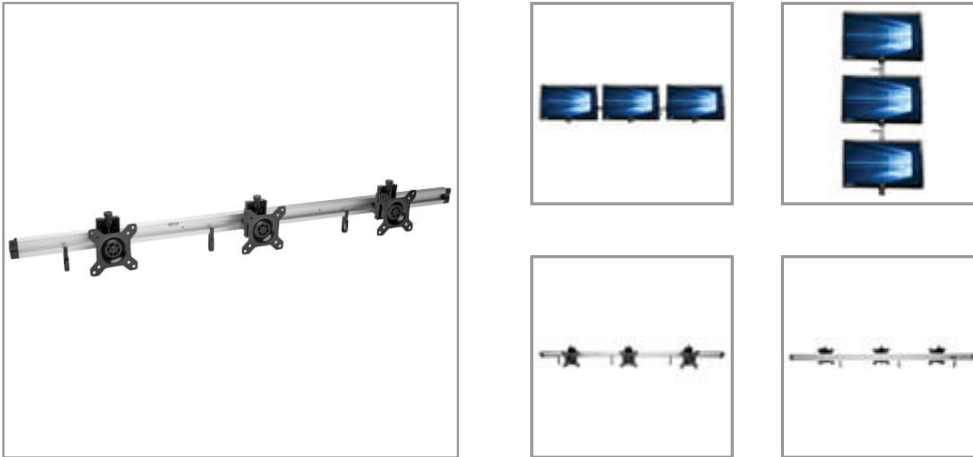

Low-profile rail mount hangs 3 flat-panel televisions, monitors or other displays on the wall. Recommended for video walls, menu boards and other applications in restaurants, bars, airports, hotels, offices and boardrooms.

### Description

The VESA-compliant DMR1015X3 Triple Flat-Panel Rail Wall Mount allows you to mount three flat-panel televisions, monitors or other displays on the wall in either portrait or landscape mode. Recommended for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms, the low-profile mount fits most flat-panel displays from 10 to 15 inches.

Up to three displays attach to VESA mounts that can slide closer or further apart along the rail for optimal viewing. The rail is concealed behind the displays for a sleek, professional appearance. Included cable guides attach to the rail to keep power cords out of the way.

Durable steel construction supports up to 18 lbs (8.2 kgs) per VESA mount. Mounting hardware is included. Conforms to VESA-compliant displays with either of the following mounting hole patterns: 75 x 75 mm and 100 x 100 mm.

### Features

#### Mounts 3 Televisions or Monitors to the Wall

- Fits most flat-panel TVs, monitors and other displays from 10 to 15 in.
- Ideal for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms
- Designed for portrait or landscape mounting

#### Convenient One-Touch Adjustment

- 20° swivel and -15° to +15° tilt capability provides comfortable viewing
- Full 360° rotation for viewing in portrait or landscape orientation

#### Innovative Rail Design

- VESA mounts adjust independently along rail
- Rail conceals behind displays for sleek, professional appearance
- Cables attach to rail to prevent tangles and clutter
- Adjustable mounting rails match up with off-center wall studs
- Wall-mounting hardware included

### Highlights

- Fits most flat-panel displays from 10 to 15 in.
- Designed for portrait or landscape mounting
- VESA mounts adjust independently along rail
- Durable steel construction
- Supports up to 18 lbs (8.2 kgs) per VESA mount

### Package Includes

- Wall rail
- (3) VESA mounts
- (12) M4 x 12 screws
- (12) M4 x 30 screws
- (12) Spacers
- (4) Cable guides
- (5) Anchor bolts
- (5) Concrete anchors
- (5) Washers
- Owner's manual



Powering Business Worldwide



#### Durable Steel Construction

- Supports up to 18 lbs (8.2 kgs) per VESA mount

#### VESA Compliance

- Supports the following VESA mounting hole patterns: 75 x 75 mm and 100 x 100 mm

## Specifications

OVERVIEW	
UPC Code	037332202819
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black; Silver
Material of Construction	Steel
VESA Pattern (mm)	75x75; 100x100
Motion	Full
Mounting Location	Wall
Degrees of Motion	-15/+15 Tilt; 20 Swivel; 360 Rotate
Minimum Screen Size (in.)	10
Minimum Screen Size (cm)	25.4
Maximum Screen Size (in.)	15
Maximum Screen Size (cm)	38.1
Maximum Weight Capacity (lbs.)	18
Maximum Weight Capacity (kg)	8
Min/Max Arm Extension (in.)	3
Min/Max Arm Extension (cm)	7.60
Number of Displays	3
Shipping Dimensions (hwd / in.)	5.04 x 50.98 x 2.44
Shipping Dimensions (hwd / cm)	12.80 x 129.49 x 6.20
Shipping Weight (lbs.)	7.77
Shipping Weight (kg)	3.52
Unit Dimensions (hwd / in.)	4.730 x 50.000 x 3.350
Unit Dimensions (hwd / cm)	12 x 127 x 6
Unit Weight (lbs.)	6.14
Unit Weight (kg)	2.79

Assembly Required	Yes
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Cord Management	Yes
Tools Necessary	Yes
Security Lock	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[DMR1015X3](#)