




Powering Business Worldwide

# Universal-Input Basic PDU G4, 208V and 415/240V, 42 Outlets, Input Cable Sold Separately, End-Entry Input, 72-Inch 0U Vertical

MODEL NUMBER: **EVBAGU23X-E**

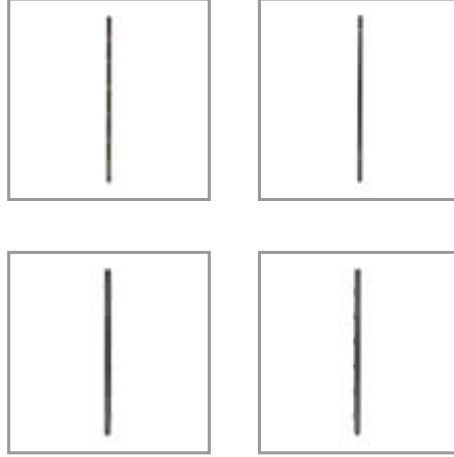

Basic UPDU accommodates both single- and 3-phase power in 208V and 415/240V environments when paired with a removable input cable.

## Features

### 17 Removable Power Cables with 15 Different Plugs Support Universal Input

This universal input PDU (UPDU) G4 is designed to meet your most diverse rack-power needs. Equipped with 42 outlets, the EVBAGU23X-E accommodates power needs ranging from 5kVA single-phase to 23kVA three-phase. Pair the UPDU with any one of 17 removable power cables with 15 different plug options (all sold separately). This UPDU alleviates the cost and complexity of mixing and matching different PDUs for different installations. It also ensures you won't outgrow your PDU as your power needs evolve.

### 42 Outlets Give You Plenty of Power Options

The EVBAGU23X-E features 24 C13 outlets, which accept C14 connectors, and 18 high-retention C39 combo outlets, which accept both C14 and C20 connectors, adding flexibility to deployments and reducing the quantity of PDUs you will need to purchase and install.

### Convenient Box-to-Rack Installation

This UPDU G4 features toolless mounting buttons that allow front- or side-facing rack installation, depending on your rack's layout and your power needs. Choose from a collection of 17 interchangeable AC input cables and 15 plug options (all power cables sold separately) that support a wide variety of voltages and capacities. Low-profile circuit breakers are flush with the lightweight aluminum chassis, and its narrow two-inch width saves space within the rack for revenue-generating equipment.

## Specifications

OVERVIEW	
UPC Code	786689812812
PDU Type	Basic
INPUT	

## Highlights

- Universal power input accommodates 5kVA single-phase to 23kVA 3-phase power
- Provides branch circuit protection for all connected equipment in your rack
- 42 outlets include 24 C13 and 18 flexible C39, which accepts C14 and C20 plugs
- Toolless mounting buttons allow 0U vertical installation in your 42U or higher rack

## Package Includes

EVBAGU23X-E Universal-Input Basic Rack PDU G4



Powering Business Worldwide

Input Phase	3-Phase; Single-Phase
PDU Input Voltage	208-240V, 415/240V, 208/120V
Nominal Input Voltage Description	1P: 100-240V~, 16-63A 3P DELTA: 100-240V~, 16-55A 3P WYE: 100-240 / 173-415V~, 16-32A 50/60Hz
Maximum Input Amps	63
Input Connection Type	Universal Input
PDU Plug Type	Hardwire
Voltage Compatibility (VAC)	1-Phase; 100; 110; 120; 200; 208; 230; 240; 3-Phase; 415
Input Cord Details	Universal input connector. Available 12 detachable power cords with 12 different plugs; all cords are 10 ft. long with locking connectors. Cordsets are sold and shipped separately.
Input Cord Length (ft.)	0
Input Cord Length (m)	0.00
<b>OUTPUT</b>	
Output Capacity (kVA)	23
Output Capacity (Watts)	23000
Output Capacity (kW)	23
Output Capacity Details	Power rating is based on the input cordset used. Cord options available for 5kVA-23kVA, 1-phase or 3-phase
Frequency Compatibility	50 / 60 Hz
Output Circuit Breakers	(6) low-profile circuit breakers. 16A (Europe)/20A (US). One circuit breaker per outlet bank.
Nominal Output Voltage(s) Supported	200V; 208V; 230V; 240V
Output Receptacles	(24) C13; (18) C39
Overload Protection	(6) 2-pole 20A circuit breakers
<b>CONNECTIONS</b>	
Daisy-chainable / Cascadable	No
<b>SURGE / NOISE SUPPRESSION</b>	
Automatic Shut-Off	No
<b>PHYSICAL</b>	
Material of Construction	Aluminum
Rack Height	0U
Form Factors Supported	Vertical
Housing Color	Black
Included Mounting Accessories	Mounting buttons
Included Mounting Accessory Description	Factory-installed shoulder-style aluminum mounting buttons. 61.25" center-to-center Alternative flush-style mounting buttons also included with PDU.
PDU Form Factor	Vertical (0U)



Powering Business Worldwide

Shipping Dimensions (hwd / in.)	75.00 x 7.72 x 5.40
Shipping Dimensions (hwd / cm)	190.50 x 19.61 x 13.72
Shipping Weight (lbs.)	15.43
Shipping Weight (kg)	7.00
Unit Dimensions (hwd / in.)	64.400 x 2.090 x 2.050
Unit Dimensions (hwd / cm)	163.57 x 5.08 x 6.50
Unit Weight (lbs.)	13.7
Unit Weight (kg)	6.21
Rack Units	42
Mounting Details	Mounting Buttons
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	32° to 140°F (0° to 60°C)
Storage Temperature Range	-13° to 149°F (-25° to 65°C)
Relative Humidity	5% to 95% non-condensing
Operating Elevation	0-10000 ft. (0-3000 m)
Storage Elevation (ft.)	0-50000 ft. (0-15240 m)
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	ICES (Canada); UL 62368-1; cTUVus
Product Compliance	CE (Europe); FCC Part 15 Class A (USA); RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	3-year limited warranty
Product Warranty Period (U.S. & Canada)	3-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eaton:](#)

[EVBAGU23X-E](#)