


# Monitor Riser for Desk - Height Adjustable, Glass Top, USB and Audio Ports

MODEL NUMBER: MR248USBG

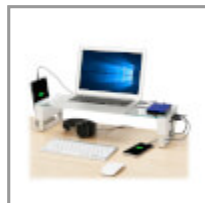

Computer monitor stand lifts your monitor up to 5.1 in. above your workstation surface to help ease eye and neck strain.

## Features

### Maintenance-Free Computer Monitor Stand Raises Your Screen for Comfortable Viewing

This desk monitor riser allows you some flexibility in placing your monitor for maximum comfort. The legs adjust to heights of 3.1 inches (80 millimeters), 4.3 inches (110 millimeters) and 5.1 inches (130 millimeters), so you can view your monitor while lessening strain on your eyes and neck. Lifting your monitor also frees up valuable space on your desk, table or counter at home, school or office.

### Rugged Glass and Aluminum Construction Supports Up to 44 Pounds

The tempered glass platform measures 22.8 x 8.3 inches (580 x 210 millimeters) and supports monitors, laptops, printers, small televisions and other devices weighing up to 44 pounds (20 kilograms). A keyboard fits beneath it when not in use to clear up useful space on your desktop.

### USB and Audio Ports Keep Essential Workplace Accessories Ready

Three USB-A ports and two Quick Charge ports allow powering and charging of phones and tablets. A pair of 3.5 mm audio ports support a microphone and speakers. A storage slot built into one end keeps necessary office supplies at your fingertips.

### Sets Up Quickly and Easily in Just a Few Seconds

This monitor stand riser assembles in moments with no tools or permanent mounting required. The legs are designed to prevent slipping on a level surface.

## Specifications

OVERVIEW	
UPC Code	037332283917
Device Compatibility	Monitor/HDTV
INPUT	

## Highlights

- Computer monitor riser easily adjusts to heights from 3.1 to 5.1 in.
- Eases eye and neck strain while clearing valuable space on your desk or table
- 3 USB ports and 2 Quick Charge ports allow charging of smartphones and tablets
- Side slot holds smartphone, notepad and other essential workspace tools
- Rectangular glass platform supports monitor or other devices up to 44 lb.

## Package Includes

- MR248USBG Monitor Riser
- USB cable
- Audio cables
- AC power adapter
- Owner's manual



Powering Business Worldwide

**TRIPP-LITE**  
by **EAT•N**

AC Power Adapter Input Specs (V / Hz / A)	100-240v, 50/60Hz; 85A
AC Power Adapter Output Specs (V / A)	12Vdc 2.0 Adapter
<b>PHYSICAL</b>	
Color	Silver
Material of Construction	Tempered glass, plastic, aluminum, silicone pad
Mounting Location	Desktop
Maximum Weight Capacity (lbs.)	44
Maximum Weight Capacity (kg)	20
Number of Displays	1
Shipping Dimensions (hwd / in.)	3.30 x 27.40 x 9.30
Shipping Dimensions (hwd / cm)	8.38 x 69.60 x 23.62
Shipping Weight (lbs.)	5.90
Shipping Weight (kg)	2.68
Unit Dimensions (hwd / in.)	5.120 x 24.130 x 8.300
Unit Dimensions (hwd / cm)	13 x 61.28 x 21.08
Unit Weight (lbs.)	4.96
Unit Weight (kg)	2.25
Assembly Required	Yes
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antimicrobial	No
Cord Management	Yes
Tools Necessary	No
Security Lock	No
Height Adjustable	Yes
Outdoor Use	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	EN 60950-1
Product Compliance	CE (Europe); FCC Part 15 Class B (USA); REACH; RoHS; RoHS3
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty



*Powering Business Worldwide*



1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[MR248USBG](#)