


Sleeve Holds 1 High-Density Copper/Fiber Cassette, 0U

MODEL NUMBER: **N484-00U**

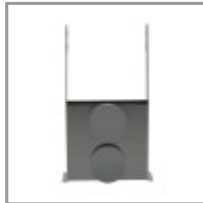

Description

The N484-00U is a compact 0U chassis that allows you to mount a single high-density copper/fiber cassette on the metal surface of any rack enclosure, cable manager or other similar structure via the attached magnets. Unlike standard rack-mount solutions, the N484-00U allows you to locate a copper/fiber cassette where standard chassis cannot go, connecting cables at the cable manager where they are being routed through. It's also perfect for adding copper/fiber connectivity where no existing rack infrastructure exists, such as a remote workstation, a new build-out or temporary install locations. Choose among a wide array of cassettes ranging from LC and MTP fiber to RJ45 copper. Fiber cassettes come in multiple variations, allowing you to connect and interconnect your 10 Gb, 40 Gb and 100/120 Gb equipment. In addition, it gives you the flexibility to add as you go, without needing to purchase a 1U chassis when you only need to add one more cassette.

Features

- Space Saving 0U design allows a Copper / Fiber Cassette to be mounted on the metal surface of any rack enclosure, cable manager or other similar structure via the attached magnets
- Unlike standard rackmount solutions, the N484-00U allows you to locate a copper / fiber cassette where standard chassis' cannot go, connecting cables at the cable manager where they are being routed through.
- It's also perfect for adding Copper / Fiber connectivity where no existing rack infrastructure exists, such as a remote work station, a new build-out, or temporary install locations
- Choose amongst a wide array of cassettes ranging from LC and MTP fiber to RJ45 copper, all in a single 0U sleeve
- Fiber cassettes allow for the connection and interconnection of 10Gb, 40Gb, and 100/120Gb equipment
- Gives you the flexibility to add as you go, without needing to purchase a 1U chassis when you only need to add one more cassette.
- Fully passive; no added heat or cooling load
- Manufactured with heavy duty, 1.0mm Cold Rolled Steel

Specifications

OVERVIEW

Highlights

- Space Saving 0U design allows a Copper / Fiber Cassette to be mounted on the metal surface of any rack enclosure, cable manager or other similar structure via the attached magnets
- Perfect for adding Copper / Fiber connectivity where no existing rack infrastructure exists, such as a remote work station, a new build-out, or temporary install locations
- Choose amongst a wide array of cassettes ranging from LC and MTP fiber to RJ45 copper, all in a single 0U sleeve
- Fiber cassettes allow for the connection and interconnection of 10Gb, 40Gb, and 100/120Gb equipment

Package Includes

- High Density Copper / Fiber Enclosure Panel, 0U, 1-Cassette Capacity



Powering Business Worldwide

TRIPP LITE
SERIES

UPC Code	037332187253
Accessory Type	Pass-Through Panel
Technology	Cat5/5e; Cat6; Cat6a; Multimode
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / in.)	2.60 x 4.80 x 9.10
Shipping Dimensions (hwd / cm)	6.60 x 12.19 x 23.11
Shipping Weight (lbs.)	0.80
Shipping Weight (kg)	0.36
Unit Dimensions (hwd / in.)	1.750 x 19.000 x 13.000
Panel Style	Cassette Type
ENVIRONMENTAL	
Operating Temperature Range	-4° to 122°F (-20° to 50°C)
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N484-00U](#)