


**Important Note**

OM3 can support 40GBASE-SR4 / 100GBASE-SR10 in applicable parallel optics networks.

**MTP/MPO Fan-out Cable with Push/Pull Tab Connectors, MTP/MPO to 4xLC, 40GbE, 40GBASE-SR4, OM3 Plenum-rated - Aqua, 2M (6.56 ft.)**

MODEL NUMBER: **N844-02M-8LC-PT**

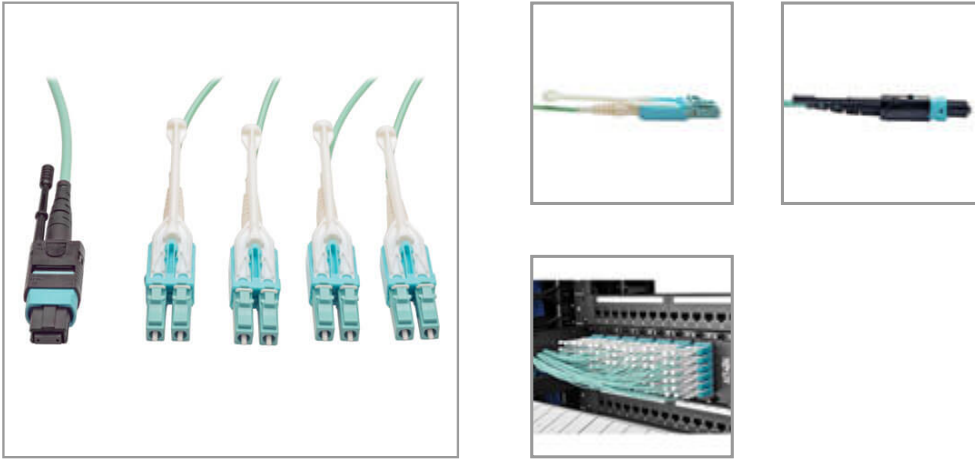

**Highlights**

- MTP / MPO to 8 x LC Fan-out Cable
- Push/Pull tab connectors offer maximum accessibility in high density installations; install / remove with one hand without needing additional tools
- Slim uniboot design saves space and makes cables easier to manage
- Premium-grade ceramic ferrule designed specifically for 10GbE and faster applications
- Sturdy plastic housing for long-lasting durability
- OM3, 40GbE rated, 40GBASE-SR4
- Backward compatible with existing 50/125 fiber
- Plenum rated jacket

**Package Includes**

- 2M (6.56-ft.) MTP / MPO Fan-out Cable, MTP/MPO to 8 x LC, 40GbE OM3 Plenum

**Features**

- MTP / MPO to 8 x LC Fan-out Cable
- Push/Pull tab connectors offer maximum accessibility in high density installations; install / remove with one hand without needing additional tools
- Slim uniboot design saves space and makes cables easier to manage
- Premium-grade ceramic ferrule designed specifically for 10GbE and faster applications
- Sturdy plastic housing for long-lasting durability
- OM3, 40GbE rated, 40GBASE-SR4
- Backward compatible with existing 50/125 fiber
- Plenum rated jacket

**Specifications**

OVERVIEW	
UPC Code	037332185266
Technology	Multimode
Optical Mode	OM3
CONNECTIONS	



Powering Business Worldwide

TRIPP LITE  
SERIES

Side A - Connector 1	12-STRAND MTP/MPO (FEMALE)
Side B - Connector 1	(8) LC DUPLEX (MALE)
Endface Polish	PC
Polarity	Type B (cross)
<b>PHYSICAL</b>	
Cable Jacket Color	Aqua
Connector Color	Aqua; Black; Aqua
Cable Jacket Material	PVC
Cable Jacket Rating	OFNP
Clad Diameter (microns)	125
Core Diameter (microns)	50
Number of Fibers	8
Cable Length (ft.)	6.6
Cable Length (m)	2.01
Cable Length (in.)	78.7
Minimum Bend Radius	20 mm (Dynamic); 10 mm (Static)
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.15
Shipping Weight (kg)	0.07
Fiber Cable Length	2M (6.6 ft)
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	-4° to 140°F (-20° to 60°C)
Storage Temperature Range	-4° to 140°F (-20° to 60°C)
Operating Humidity Range	5% to 85% RH, Non-Condensing
Storage Humidity Range	35% to 65% RH, Non-Condensing
<b>COMMUNICATIONS</b>	
Network Compatibility	40 Gbps; 100 Gbps; 400 Gbps
Attenuation @ 850NM	3.0 dB/km
Insertion Loss	0.35 dB
<b>FEATURES &amp; SPECIFICATIONS</b>	
Push/Pull Tabs	Yes
Breakout	Yes



Powering Business Worldwide

TRIPP LITE  
SERIES

Trunk	Yes
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; REACH
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N844-02M-8LC-PT](#)