


Keyspan Mini DisplayPort to Active VGA Adapter, Video Converter (M/F), White, 6-in. (15.24 cm)

MODEL NUMBER: **P137-06N-VGA**

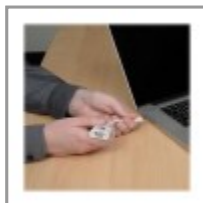

Connect a VGA monitor to a Mac or PC with a Mini Displayport output

Features

- Connect a VGA monitor to a Mac or PC with a Mini Displayport output
- Compatible with Thunderbolt 1 and 2 ports on Mac computers
- Plug-and-play convenience—no drivers or software needed
- Supports computer video resolutions up to 1920 x 1200, and HD resolutions up to 1080p
- Ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals
- Converts both Single-Mode and Dual Mode (DP++) Displayport output

Highlights

- Connect a VGA monitor to a Mac or PC with a Mini Displayport output
- Compatible with Thunderbolt 1 and 2 ports on Mac computers
- Plug-and-play convenience—no drivers or software needed
- Supports computer video resolutions up to 1920 x 1200, and HD resolutions up to 1080p
- Ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals
- Converts both Single-Mode and Dual Mode (DP++) Displayport output

System Requirements

- Mac or PC with a Mini Displayport port; Compatible with Thunderbolt 1 and 2 ports on Mac computers
- Monitor with a VGA port
- Not for use with MST Hubs. For compatibility with MST Hubs, use a Displayport 1.2 compliant product such as P137-06N-VGA-V2

Package Includes

- Mini-DisplayPort to Active VGA Adapter

Specifications

OVERVIEW	
UPC Code	037332158901
Product Type	Video Adapter
Technology	VGA/SVGA; DisplayPort
CONNECTIONS	
Side A - Connector 1	MINI DISPLAYPORT (MALE)
Side B - Connector 1	HD15 (FEMALE)
PHYSICAL	
Color	White



Powering Business Worldwide

TRIPP LITE
SERIES

Cable Length (ft.)	0.5
Cable Length (m)	0.15
Cable Length (in.)	6
Cable Length (cm)	15.24
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.01
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 0.03
Shipping Weight (lbs.)	0.05
Shipping Weight (kg)	0.02
ENVIRONMENTAL	
Operating Temperature Range	32° to 158°F (0° to 70°C)
Storage Temperature Range	14° to 176°F (-10° to 80°C)
Operating Humidity Range	10% ~ 85% RH
Storage Humidity Range	5% ~ 90% RH
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; Trade Agreements Act (TAA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	3-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[P137-06N-VGA](#)