


## Protect It! 10-Outlet Surge Protector, 8 ft. (2.43 m) Cord, 3345 Joules, Tel/Modem/Coaxial Protection

MODEL NUMBER: TLP1008TELTV

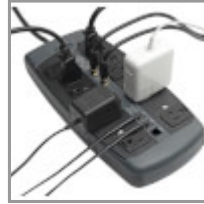

### Highlights

- 10 NEMA 5-15R outlets, including 4 for bulky transformers
- 8-ft. (2.43 m) cord with right angle NEMA 5-15P plug
- 1 in/2 out tel/modem surge protection
- 1 line 2.2GHz gold coaxial protection
- 3345 joule rating

### Package Includes

- TLP1008TELTV surge suppressor
- 6-ft. RJ11 cable
- 6-ft. (1.83 m) gold coax cable
- Instruction manual and warranty information

### Description

The TLP1008TELTV offers economical AC surge suppression for protection of workstations, PCs, telecom systems, home electronics and other sensitive equipment. The TLP1008TELTV features 10 outlets, an eight-foot (2.4 meters) cord with a space-saving right-angle plug, and diagnostic LEDs to warn of suppressor damage. The unit has a surge suppression rating of 3345 joules to shield equipment from line noise and the strongest surges. Built-in RJ11 jacks prevent surges from damaging your modem/fax/phone equipment. Built-in 2.2 GHz gold coax jacks prevent surges from damaging your cable/satellite equipment.

### Features

- 10 outlets with child safety covers
- 8-ft. (2.43 m) cord with space-saving right-angle plug
- Built-in RJ11 jacks prevent surges from damaging your modem/fax/phone equipment; - built-in splitter protects two devices sharing a single line; 6-ft. (1.83 m) telephone cord included
- Built-in 2.2GHz gold coax jacks prevent surges from damaging your cable/satellite equipment; 6-ft gold coax cable included
- Surge suppression rating: 3345 joule protection
- EMI/RFI noise filtering
- 15 amp resettable circuit breaker
- Diagnostic LEDs confirm suppressor "protection present" (green) and "grounded" (red) status
- Includes full normal mode (H-N) and common mode (N-G/H-G) line surge suppression
- Can accommodate up to 4 transformers without blocking remaining outlets
- Keyhole supports for wall mounting
- \$150,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only) covers connected equipment
- Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required
- Lighted power switch

## Specifications



Powering Business Worldwide

**TRIPP-LITE**  
by **EATON**

| OVERVIEW                           |   |
|------------------------------------|---|
| UPC Code                           | 037332119070  |
| INPUT                              |   |
| Nominal Input Voltage(s) Supported | 120V AC   |
| Recommended Electrical Service     | 120V (110-125V)   |
| Input Cord Gauge Type              | 14 gauge; SJT   |
| Input Cord Gauge (AWG)             | 14  |
| Voltage Compatibility (VAC)        | 120   |
| Maximum Surge Amps                 | 135000  |
| Input Plug Type                    | NEMA 5-15P  |
| Input Cord Details                 | SJT   |
| Input Cord Length (ft.)            | 8   |
| Right-Angle Plug                   | Yes   |
| Input Cord Length (m)              | 2.44  |
| Integrated Cord Clip               | No  |
| OUTPUT                             |   |
| Frequency Compatibility            | 50 / 60 Hz  |
| Output Receptacles                 | (10) 5-15R  |
| Circuit Breaker (amps)             | 15  |
| Overload Protection                | 15A resettable circuit breaker  |
| Transformer Accommodation          | (8) Yes   |
| Outlet Orientation                 | Two rows of outlets, including 4 widely spaced for transformers                           |
| Right-Angle Outlets                | No  |
| Outlet Safety Covers Detail        | Includes built-in sliding outlet safety covers  |
| USER INTERFACE, ALERTS & CONTROLS  |   |
| Diagnostic LED(s)                  | Yes   |
| Switches                           | Two-position on/off power switch  |
| Diagnostic LED Details             | Built-in LEDs confirm suppressor "protection present" (green) and "grounded" (red) status |
| SURGE / NOISE SUPPRESSION          |   |
| AC Suppression Joule Rating        | 3345  |
| AC Suppression Response Time       | < 1 ns  |
| Protection Modes                   | Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression              |
| UL1449 Let Through Rating          | 400V - UL Verified  |



Powering Business Worldwide

**TRIPP-LITE**  
by **EATON**

|   |  |
|---|--|
| EMI / RFI Filtering                               | Up to 40 dB  |
| Automatic Shut-Off                                | Yes  |
| <b>DATALINE SURGE SUPPRESSION</b>                 |  |
| Telephone/DSL Protection Details                  | 1 line   |
| Cable (Coax) Protection                           | Yes  |
| Cable (Coax) Protection Details                   | 1 line   |
| Network (Ethernet) Protection                     | No   |
| Telephone/DSL Protection                          | Yes  |
| <b>PHYSICAL</b>                                   |  |
| Material of Construction                          | Plastic  |
| Power Cord Color                                  | Black  |
| Housing Color                                     | Black  |
| Mounting Holes or Slots                           | Yes  |
| Slot or Hole Mount Measurement (Center to Center) | 108 mm   |
| Outlets Measurement (Center to Center)            | Between Standard Outlets = 28.4mm; Between Standard and Transformer Outlets = 56.8mm                               |
| Receptacle Color                                  | Black  |
| Shipping Dimensions (hwd / in.)                   | 14.40 x 2.50 x 8.20  |
| Shipping Dimensions (hwd / cm)                    | 36.58 x 6.35 x 20.83   |
| Shipping Weight (lbs.)                            | 2.70   |
| Shipping Weight (kg)                              | 1.22   |
| Unit Dimensions (hwd / in.)                       | 11.800 x 5.300 x 1.800   |
| Unit Dimensions (hwd / cm)                        | 29.5 x 12.7 x 6.5  |
| Unit Weight (lbs.)                                | 2.2  |
| Unit Weight (kg)                                  | 1.00   |
| <b>FEATURES &amp; SPECIFICATIONS</b>              |  |
| Rotatable Outlets                                 | No   |
| Antimicrobial                                     | No   |
| <b>STANDARDS &amp; COMPLIANCE</b>                 |  |
| Product Certifications                            | CAN/CSA-C22.2 No. 269.3 (Canada); CAN/CSA-C22.2 No. 308 (Canada); cUL Listed; UL 1449; UL 497A; UL 1363; UL Listed |
| Product Compliance                                | RoHS   |
| <b>WARRANTY &amp; SUPPORT</b>                     |  |

|  |  |
|--|--|
| Product Warranty Period (Worldwide)                        | Lifetime limited warranty  |
| Connected Equipment Insurance (U.S., Canada & Puerto Rico) | \$150,000 <a class="insuranceLink" href="//tripplite.eaton.com/support/insurance-policy">Ultimate Lifetime Insurance</a> |

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[TLP1008TELT](#)