


Safe-IT 6-Outlet Surge Protector, 2 USB Charging Ports, 8 ft. Cord, 5-15P Plug, 2100 Joules, Antimicrobial Protection, Black

MODEL NUMBER: TLP608DMUAM

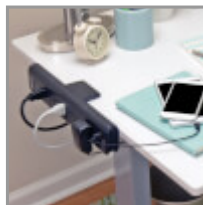

Clamp-on surge protector with antimicrobial protection safeguards your valuable electronics against dangerous surges, spikes and line noise.

Features

6-Outlet Surge Protector with USB Safeguards Your Sensitive Electronics

Ideal for your home, office, retail or industrial workstation, this Safe-IT™ surge protector features a surge protection rating of 2100 joules to defend your valuable electronic components against power surges and spikes. Because residential power outlets have three wires—hot line (H), neutral (N) and ground (G)—the TLP608DMUAM protects all three, covering the two protection modes: full normal mode (H-N) and common mode (N-G/H-G).

NEMA 5-15R Outlets Accept a Wide Range of Electronic Devices

Plug your computer, printer, wireless router, desk lamp and other home/office electronics into six NEMA 5-15R outlets to protect them against dangerous surges, spikes and line noise. Two outlets are separated from the others to allow connection of bulky transformers without blocking adjacent outlets.

2 USB Ports Share 2.4 Amps of Charging Power

Two USB-A ports are available for charging your smartphone, tablet or other USB mobile devices. They share 2.4A for charging multiple devices at the same time.

Premium Protection from EMI/RFI Line Noise Helps Your Equipment Perform Better

This surge protector filters out disruptive EMI (electromagnetic interference) and RFI (radio frequency interference) line noise that can disturb your electronics and inflict hardware damage or data loss. This EMI/RFI filtering also helps your connected components perform better and last longer.

Includes the Latest Safety Features to Maintain Your Equipment's Well-Being

The lighted on/off switch allows you easy one-touch control over equipment connected to the strip. LEDs confirm at a glance that the wall outlet is grounded and your connected equipment is protected. An integrated 15-amp resettable circuit breaker helps prevent equipment damage due to overloads. Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required.

Antimicrobial Protection Helps Provide a Safer, Cleaner and Healthier Work Environment

The TLP608DMUAM features antimicrobial protection that helps resist the growth of bacteria, viruses, fungi, mold and mildew.

Highlights

- 6 NEMA 5-15R outlets distribute AC power to connected home/office equipment
- 2100 joules protect your valuable electronics against dangerous surges and spikes
- USB-A ports share 2.4A for fast charging of phones and other mobile devices
- Clamp attaches to desk, workbench or most hard surfaces. Clamp adjust from .39 to 1.38"
- 8 ft. braided input cord allows flexibility in placing devices away from wall outlet
- Antimicrobial protection helps resist the growth of bacteria, viruses, fungi, mold and mildew

Applications

- Protect computers, peripherals, home theater equipment and other valuable electronics against AC power surges and spikes
- Filter potentially damaging line noise to improve connected equipment's performance and lifespan
- Safeguard valuable data against damage stemming from unexpected surges
- Clamp to desk, workbench or almost any hard surface. Clamp adjusts from .39 to 1.38"
- Charge smartphones, tablets or other USB devices via USB ports

Package Includes

- TLP608DMUAM 6-Outlet Surge Protector, Black
- Owner's manual



Powering Business Worldwide



Versatile Surge Protector Provides Multiple Installation Options

This surge protector with eight-foot (2.4-meter) braided AC input cord and NEMA 5-15P plug gives you flexibility in placing the unit away from the nearest wall outlet. Its mounting clamps adjust from 0.4 to 1.6 inches (1 to 4 centimeters) to secure the TLP608DMUAM on desks, tables, poles and other surfaces.

Specifications

OVERVIEW	
UPC Code	037332263605
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge Type	14 gauge; SJT
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	8
Right-Angle Plug	No
Input Cord Length (m)	2.44
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output Receptacles	(6) 5-15R
Circuit Breaker (amps)	15
Overload Protection	15A resettable illuminated combo switch / circuit breaker
Transformer Accommodation	(3) Yes
Outlet Orientation	Single row of 6 outlets
Right-Angle Outlets	No
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes
Switches	Combination AC circuit breaker and 2 position red illuminated on/off power switch
Diagnostic LED Details	Built-in LED confirms suppressor "protection present" (green) status, grounded (red) status
CHARGING	



Powering Business Worldwide

TRIPP-LITE
by **EAT•N**

Number of Charging Ports	2
Total Charging Amps	2.4A
Total Charging Watts	12
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 2.4A
Overcharge Protection	No
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	2100
AC Suppression Response Time	< 1 ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
UL1449 Let Through Rating	400V
EMI / RFI Filtering	Yes
Automatic Shut-Off	Yes
DATALINE SURGE SUPPRESSION	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
PHYSICAL	
Color	Black
Material of Construction	Plastic
Power Cord Color	Black/gray braided cord
Housing Color	Black
Mounting Holes or Slots	No
Receptacle Color	Black
Shipping Dimensions (hwd / in.)	3.00 x 5.60 x 16.50
Shipping Dimensions (hwd / cm)	7.62 x 14.22 x 41.91
Shipping Weight (lbs.)	1.80
Shipping Weight (kg)	0.82
Unit Dimensions (hwd / in.)	2.890 x 13.600 x 2.870
FEATURES & SPECIFICATIONS	
Rotatable Outlets	No
Antimicrobial	Yes

GaN Technology	No
Antibacterial	No
STANDARDS & COMPLIANCE	
Product Certifications	cUL Listed; NOM (Mexico); UL 1449; UL 1363; UL Listed
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$40,000 Ultimate Lifetime Insurance

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[TLP608DMUAM](#)