


Wireless Charging Stand - 10W Fast Charging, Apple and Samsung Compatible, Black

MODEL NUMBER: U280-Q01ST-BK

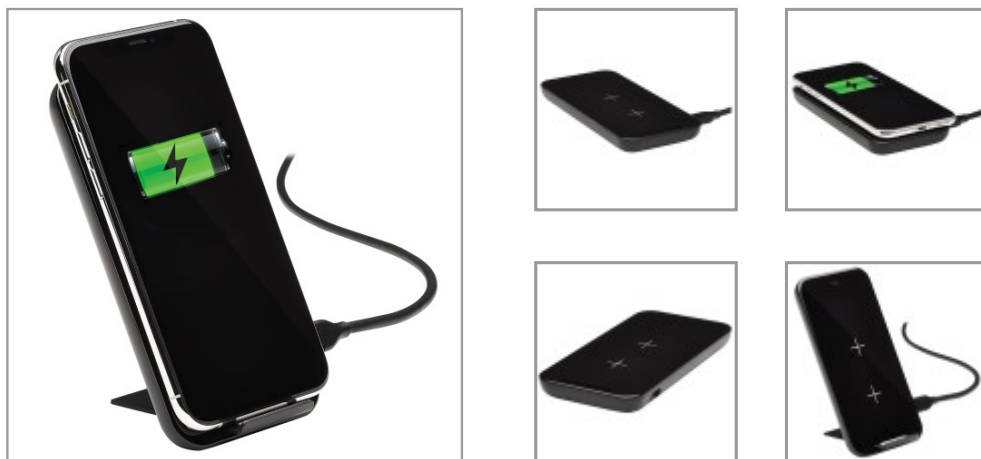

Wireless fast-charging stand transfers battery power to your device without connecting a troublesome cable between them.

Features

Wireless Cell Phone Charger Delivers up to 10W for Apple and Samsung Phones Who wants to plug and unplug cords when you just want to charge your cell phone? The U280-Q01ST-BK makes charging more convenient by doing it wirelessly. Just place your Qi-certified device on the charging stand. That's all there is to it. This wireless phone charger even works through most protective phone cases up to 5 millimeters. Note: please remove any magnetic or metal objects from your phone or case before charging.

Compatible with Qi-Certified Cell Phones to Ensure a Safe, Flawless Charge The U280-Q01ST-BK charges all Qi smartphones from Apple, Sony, LG, Samsung, Nokia and other popular brands in either portrait or landscape orientation. It protects your expensive device from overheating and overcharging that could lead to internal damage. The Smart LED flashes blue to indicate the charging process is underway and changes to a solid blue to let you know your phone is at 100%.

Compact Stand Fits Comfortably on Any Counter, Table or Workspace The portable lightweight stand is just five inches in height and fits easily on your desktop or bedside table. An included USB cable connects the charger to a user-supplied QC USB wall charger or power adapter (QC 2.0 or 3.0 adapter is recommended for high-speed charging).

Specifications

OVERVIEW	
UPC Code	037332253651
Product Type	Wireless Charger
Charging Form Factor	Pad/Stand
Device Compatibility	Phone; Tablet; Amazon Kindle; Headphones; Watch
Technology	USB; Wireless

Highlights

- Charges your Apple, Google or Samsung smartphone wirelessly without a cable
- LED flashes blue during charging and turns solid blue to indicate device is fully charged
- Charges your smartphone through its protective case to avoid the hassle of removing it
- Prevents overheating and overcharging to protect your essential device from damage
- Universally compatible with all Qi-certified smartphones and other devices

Applications

- Transfer power from a wall charger or power adapter to your smartphone's battery without the burden of carrying and connecting extra cabling

System Requirements

- Compatible with all Qi-certified smartphones, including Apple iPhone 11 Pro Max/11 Pro/11/XS Max/XS/XR/8/8 Plus; Samsung S7-S10 Series and Note 8-10 Series; Google Pixel 4 XL/Pixel 4/Pixel 3 XL/Pixel 3; and Nokia 9 PureView/8 Sirocco

Package Includes

- U280-Q01ST-BK Wireless Charging Stand, Black
- USB 2.0 A to USB-C cable, 3 ft.
- Quick Start Guide



Powering Business Worldwide

TRIPP-LITE
by **EAT•N**

INPUT	
Nominal Input Voltage(s) Supported	9V DC
Input Plug Type	USB-C (FEMALE)
Input Plug Type Details	USB-A to USB-C Cable Included
OUTPUT	
Output Capacity (Watts)	10
Overload Protection	Yes
POWER	
Power Consumption (Watts)	10.00
USB Power Delivery (PD) Charging Support	No
CONNECTIONS	
Number of Ports	1
Side A - Connector 1	USB C (FEMALE)
Side B - Connector 1	WIRELESS CHARGING COIL
USER INTERFACE, ALERTS & CONTROLS	
LED Indicators	Blue and Red (Flashes Twice) = Unit Powered On/Low Voltage Reset; Blue (Solid) = Charging; Red (Solid) = Finished Charging/Standby (No Device Charging), Overheating (With Device Charging); Red (Flashing) = Charging Error
CHARGING	
Number of Charging Ports	0
Total Charging Amps	1.1A
Total Charging Watts	10
Charging Method	Wireless
Charging Method Detail	Qi Compatible
Charging Port Type	WIRELESS CHARGING COIL
Charging Ports Details	5V/1A (5W); 9V/1.1A (10W)
PHYSICAL	
Color	Black
Material of Construction	PCB, ABS
Unit Dimensions (hwd / in.)	5.500 x 2.750 x 0.550
Unit Packaging Type	Box
Unit Weight (lbs.)	0.331



Powering Business Worldwide



Unit Weight (kg)	0.15
ENVIRONMENTAL	
Operating Temperature Range	32° to 95°F (0° to 35°C)
Storage Temperature Range	-4° to 158°F (-20° to 70°C)
Operating Humidity Range	10% to 80% RH
Storage Humidity Range	5% to 95% RH
FEATURES & SPECIFICATIONS	
GaN Technology	No
Overcurrent Protection	Yes
Overvoltage Protection	Yes
Over Current Protection	Yes
Quick Charge Compliant	No
Driver Required	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[U280-Q01ST-BK](#)