



Products ▾

Materials ▾

Applications ▾

Custom Parts ▾


Service & Support ▾

Search Products



CD Series

Threaded Plastic Caps for Flared JIC Fittings

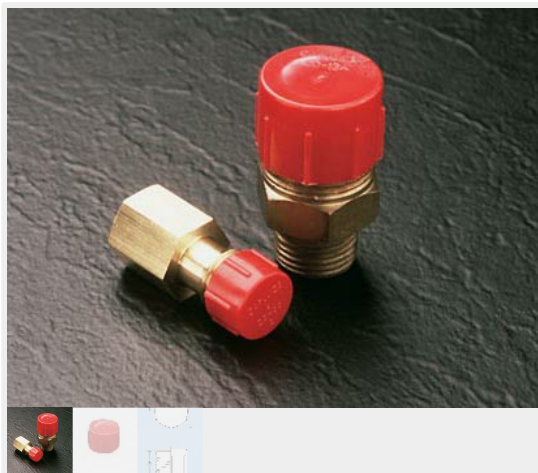

CD Series threaded plastic caps seal flared JIC fittings exceptionally well against dirt and moisture. This series can also be used for masking during painting and plating.

- Knurled for ease of application

Material: Low-Density Polyethylene

Standard Color: Red

Diagram <

Item #	Dim A (IN)	No. of Knurls	To Fit Thread Size	To Fit Tube Size		
CD-2	0.22	4	1/4-36	-	+ Available Options	Request Sample
CD-3	0.47	4	3/8-24	3/16	+ Available Options	Request Sample
CD-4	0.47	4	7/16-20	1/4	+ Available Options	Request Sample
CD-41	0.30	4	7/16-24	1/4	+ Available Options	Request Sample
CD-5	0.47	6	1/2-20	5/16	+ Available Options	Request Sample
CD-TC-40	0.31	6	1/2-20	5/16	+ Available Options	Request Sample
CD-TC-42	0.88	6	1/2-20	5/16	+ Available Options	Request Sample
CD-6	0.53	6	9/16-18	3/8	+ Available Options	Request Sample
CD-TC-6	0.47	6	5/8-18	3/8	+ Available Options	Request Sample
CD-6A	0.53	6	5/8-18	3/8	+ Available Options	Request Sample
CD-TC-63	0.75	6	5/8-18	3/8	+ Available Options	Request Sample
CD-67	0.41	6	5/8-24	-	+ Available Options	Request Sample
CD-8	0.57	6	3/4-16	1/2	+ Available Options	Request Sample
CD-TC-8-R	0.63	6	3/4-16	1/2	+ Available Options	Request Sample
CD-TC-82	0.69	6	3/4-18	-	+ Available Options	Request Sample
CD-TC-9	0.50	6	3/4-20	-	+ Available Options	Request Sample
CD-10	0.68	6	7/8-14	5/8	+ Available Options	Request Sample
CD-101	0.44	6	7/8-18	5/8	+ Available Options	Request Sample
CD-TC-111	0.78	6	7/8-18	5/8	+ Available Options	Request Sample
CD-TC-100	0.72	6	7/8-20	5/8	+ Available Options	Request Sample
CD-11	0.78	8	1-14	-	+ Available Options	Request Sample

Item #	Dim A (IN)	No. of Knurls	To Fit Thread Size	To Fit Tube Size		
CD-TC-120	0.78	8	1-20	-	+ Available Options	Request Sample
CD-12	0.75	8	1-1/16-12	3/4	+ Available Options	Request Sample
CD-TC-14	0.75	8	1-1/16-14	3/4	+ Available Options	Request Sample
CD-TC-15	0.47	8	1-1/8-18	-	+ Available Options	Request Sample
CD-14	0.94	8	1-3/16-12	7/8	+ Available Options	Request Sample
CD-16	0.84	8	1 5/16-12	1	+ Available Options	Request Sample
CD-TC-17	0.47	8	1-1/4-18	-	+ Available Options	Request Sample
CD-TC-18	0.88	8	1-5/16-12	-	+ Available Options	Request Sample
CD-TC-19	0.47	8	1-3/8-18	-	+ Available Options	Request Sample
CD-18	0.75	8	1-1/2-12	-	+ Available Options	Request Sample
CD-TC-20	0.91	8	1-5/8-12	1-1/4	+ Available Options	Request Sample
CD-22	0.94	8	1-3/4-12	-	+ Available Options	Request Sample
CD-TC-21	1.00	8	1-7/8-12	1-1/2	+ Available Options	Request Sample
CD-400	1.16	12	3-12	-	+ Available Options	Request Sample



[Shopping Cart](#) [Contact Us](#) [About Us](#) [Awards](#) [Returns](#) [Privacy](#) [Terms & Conditions](#)

Quick Links: [About Us](#) [Military & NAS Specifications](#) [Quality Certifications & Regulatory Info](#) [Cross Reference](#)

Products [Plastic Caps](#) [Plastic Plugs](#) [Masking](#) [Tubing, Netting, & Containers](#) [More Product Protection](#) [Hose Guard / Spiral Wrap](#) [Tri-Star Thread Protectors](#) [Evergreen Labware](#)

Materials [Polyethylene](#) [Vinyl](#) [Silicone](#) [Molded Rubber](#) [PETG](#) [Additional Materials](#) [Material Specification](#)

Applications [Masking](#) [Medical](#) [Evergreen Labware](#) [Thread & Flange Protection](#) [Tri-Star Thread Protectors](#) [Automotive](#) [Electronics](#) [Hydraulics](#) [Compressed Gas](#) [Packaging & Netting](#) [Aviation](#) [Hose Guard / Spiral Wrap](#)

Custom Parts [Design A Part](#) [Molding Capabilities](#)

Service & Support [Find a Sales Representative](#) [Learning Center](#) [Download Catalog](#) [Request a Quote](#) [Contact Us](#) [Quality](#) [Patents](#) [Press Room](#) [Awards](#) [Join Our Team](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Caplugs:](#)

[CD-8](#)