

FEATURES

- ※Low profile 1.6mm height
- ※Gold contact for high reliability
- ※Top tape type for washing process


APPLICATION

- ※Industrial control
- ※Automatic machines control
- ※NB, electronic devices

SPECIFICATION

| | |
|-----------------------|--------------------|
| Contact Rating | 25mA, 24V DC |
| Contact Resistance | 100mΩ max. |
| Insulation Resistance | 100MΩ min. 500V DC |
| Dielectric Strength | 300V AC/1 minute |
| Operating Force | 500gf max. |
| Travel | 0.6mm |
| Operating Life | 1,000 cycles |
| Operating Temp. | -40°C ~ +85°C |
| Storage Temp. | -40°C ~ +85°C |


CIRCUIT

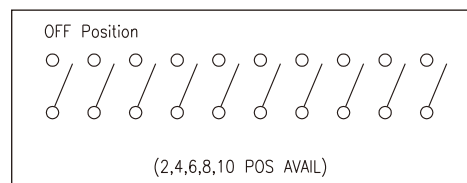



PACKAGE

- <Tube>**
DHN(F)-02: 125 pcs
DHN(F)-04: 75 pcs
DHN(F)-06: 54 pcs
DHN(F)-08: 40 pcs
DHN(F)-10: 33 pcs
- <Tape & Reel>**
DHN: 4000 pcs
DHNF: 2500 pcs



HOW TO ORDER

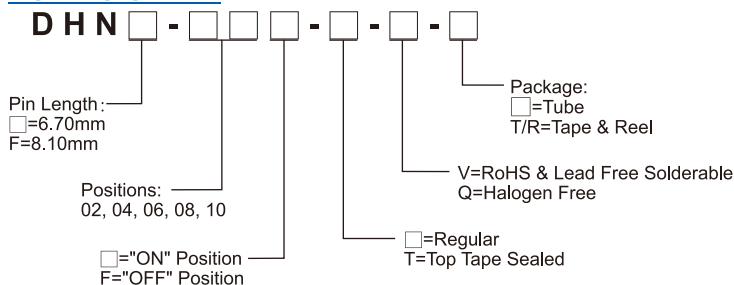

DHN

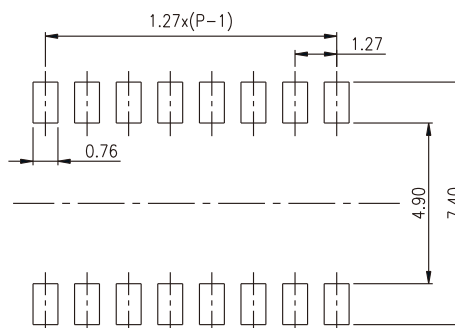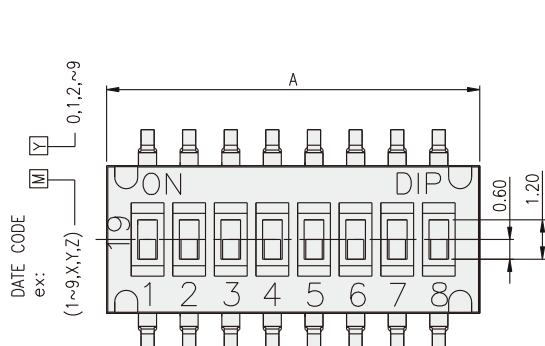



P.C.B. LAYOUT

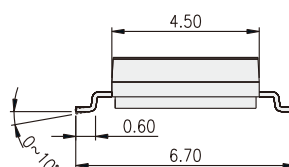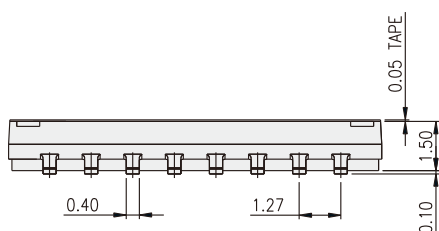



| PART NO. | NO.OF POS | DIM A |
|----------|-----------|-------|
| DHN-02 | 2 | 3.77 |
| DHN-04 | 4 | 6.31 |
| DHN-06 | 6 | 8.85 |
| DHN-08 | 8 | 11.39 |
| DHN-10 | 10 | 13.93 |

DHNF

DIP SWITCH

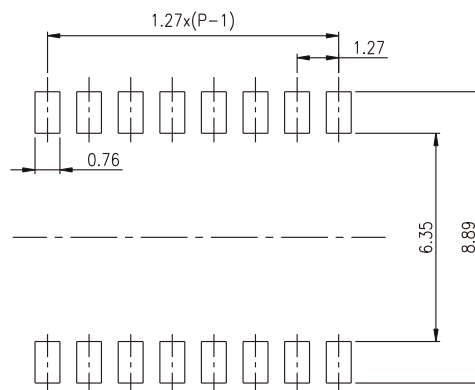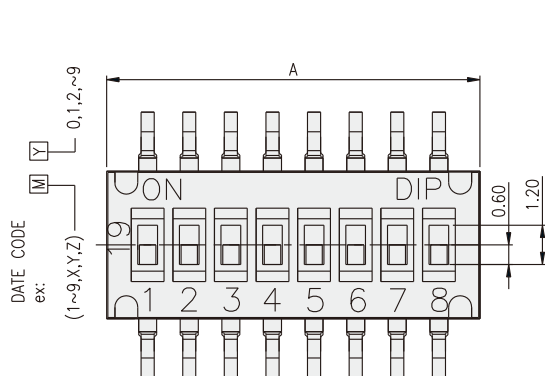

P.C.B. LAYOUT

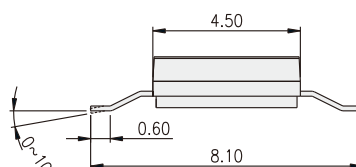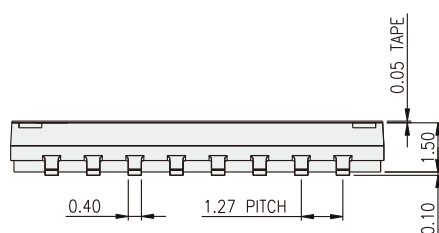

| PART NO. | NO.OF POS | DIM A |
|----------|-----------|-------|
| DHNF-02 | 2 | 3.77 |
| DHNF-04 | 4 | 6.31 |
| DHNF-06 | 6 | 8.85 |
| DHNF-08 | 8 | 11.39 |
| DHNF-10 | 10 | 13.93 |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Diptronics:](#)

[DHN-06F-T-Q-T/R](#) [DHN-04F-T-Q-T/R](#)