

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190270034

Status:


Active

Overview:

Application Tooling

Description:

ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press

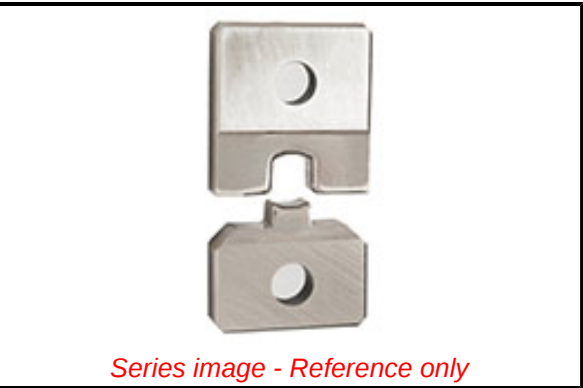

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207126
Comments	The Crimp Tape Module 640162000 is a base unit that will work like an applicator in a Molex TM-3000 638017200 , 638017300 industry standard crimp press or the Molex TM-4000 638017600 industry standard crimp press. The Crimp Tape Module will accept all ATP-301 and ATP-201 style crimp dies. This Crimp Tape Module will allow customers to process most of Molex's Mylar Tape product from 2 AWG uninsulated and 4 AWG insulated products and up. The Crimp Tape Module will NOT work in any other industry standard crimp press or wire process machine. These ATP-301 style die sets can be used in the older style suitcase presses.
Function	Crimp
Geographic Area	Global
Level of Automation	Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Crimp Module
UPC	800753040953
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.
Material Info	
Engineering Number	ATP-AA-110
Reference - Drawing Numbers	
Application Tooling Documents	ATS-190270034-001, ATS-TOOLING-ID-ATP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001,

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207126 Series

Use With

Molex Crimp Tape Module 640162000 used with Molex TM-3000: 638017200 , 638017300 , Molex TM-4000: 638017600 , Molex ATP-301 Press: 192280030 and Molex ATP-101 style presses.

Application Tooling Description	FAQ Product #
Krimptite Ring	190690028
Tongue Terminal for 18-22 AWG Wire	
Krimptite Ring	190690030
Tongue Terminal for 18-22 AWG Wire	
Krimptite Ring	190690032
Tongue Terminal for 18-22 AWG Wire	
Krimptite Ring	190690034
Tongue Terminal for 18-22 AWG Wire	
Krimptite Ring	190690036
Tongue Terminal for 18-22 AWG Wire	

TM-640160065TH-001, TM-640160065TW-001,
TM-640160065VN-001

Krimptite Ring	<u>190690038</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Ring	<u>190690044</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Ring	<u>190690046</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Ring	<u>190690050</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Ring	<u>190690055</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Ring	<u>190690057</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Ring	<u>190690062</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Snap	<u>190980019</u>
Spade Tap for 18-22	
AWG Wire, Stud	
Size 5-6 (M3-3.5),	
Mylar Tape Carrier	
Krimptite Snap	<u>190980080</u>
Spade Tap for 18-22	
AWG Wire, Stud	
Size 8 (M4), Mylar	
Tape Carrier	
Krimptite Snap	<u>190980081</u>
Spade Tap for 18-22	
AWG Wire, Stud	
Size 10 (M5), Mylar	
Tape Carrier	
Krimptite Flanged	<u>191180022</u>
Spade Tongue	
Terminal for 18-22	
AWG Wire, Stud	
Size 6 (M3.5),	
Length 14.12mm,	
Mylar Tape Carrier	
Krimptite Flanged	<u>191180024</u>
Spade Tongue	
Terminal for 18-22	
AWG Wire, Stud	
Size 8 (M4), Mylar	
Tape Carrier	
VersaKrimp Ring	<u>191930008</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930011</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930013</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930015</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930017</u>
Tongue Terminal for	
18-22 AWG Wire	

VersaKrimp Ring	<u>191930022</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930024</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930035</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930037</u>
Tongue Terminal for	
18-22 AWG Wire	
VersaKrimp Ring	<u>191930042</u>
Tongue Terminal for	
18-22 AWG Wire	
Krimptite Wire Pin	<u>192110004</u>
Terminal for 22-18	
AWG Wire, Mylar	
Tape Carrier	
VersaKrimp Metric	<u>193230207</u>
Ring Terminal for	
M2.5 Stud Size	
(#4), Un-insulated,	
Adhesive Tape on	
Reel	
VersaKrimp Metric	<u>193230208</u>
Ring Terminal for M3	
Stud Size (#5), Un-	
insulated, Adhesive	
Tape on Reel	
VersaKrimp Metric	<u>193230209</u>
Ring Terminal	
for M3-3.5 Stud	
Size (#5-#6), Un-	
insulated, Adhesive	
Tape on Reel	
VersaKrimp Metric	<u>193230210</u>
Ring Terminal for M4	
Stud Size (#8), Un-	
insulated, Adhesive	
Tape on Reel	
VersaKrimp Metric	<u>193230211</u>
Ring Terminal for M5	
Stud Size (#10), Un-	
insulated, Adhesive	
Tape on Reel	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19027-0034](#)