

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0395337808**
Status: **Active**
Overview: Eurostyle Terminal Blocks
Description: 5.08mm Pitch Eurostyle Vertical Plug, with Standard Imprinting, Rear Wire Entry, Green Housing, Gold (Au) Plated, 8 Circuits

Documents:

[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[3D Model \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks
Series [39533](#)
Application N/A
Comments with Standard Imprinting|Rear Wire Entry
Component Type Plug
Overview [Eurostyle Terminal Blocks](#)
Product Name ESE, Eurostyle Pluggable
Type Euro Block
UPC 822350533072

Physical

Circuits (Loaded) 8
Entry Angle Horizontal
Lock to Mating Part Yes
Number of Rows 1
Orientation Vertical
Panel Mount No
Pitch - Mating Interface 5.08mm
Pitch - Termination Interface 5.08mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40° to +105°C
Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm² 0.13-3.31

Electrical

Current - Maximum per Contact 18.0A
Voltage - Maximum 300V


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Product Specification PS-39500-001-001
Sales Drawing SD-39533-002

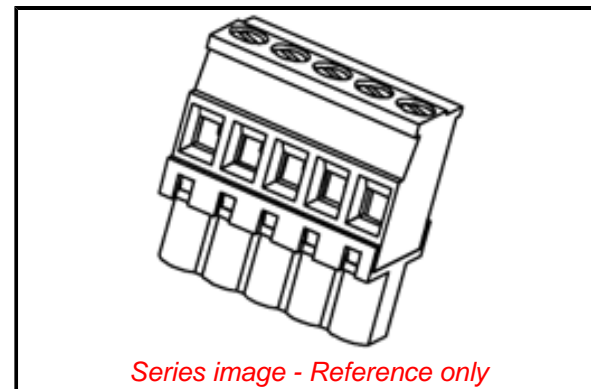

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[39533](#) Series

Mates With

[39531](#) Vertical PCB Header, [39532](#) Horizontal PCB Header, Most 5.08mm Pitch Industry Standard PCB Headers, [39538](#) Dual Level Header, Open Ends

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39533-7808](#)