


MUELLER®

MODEL: BU-P5169-*

Banana Plug (In-Line)

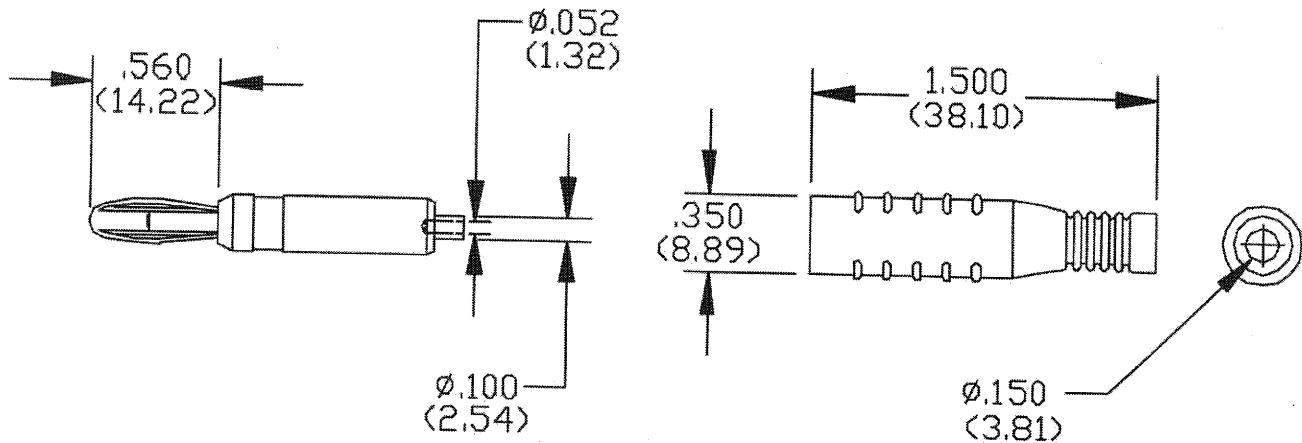

MATERIALS:

Body – Nickel Plated Brass

Insulator – Flexible PVC. Comes in -0 Black, -2 Red

For use with 18, 20 and 22 AWG wires. Can be soldered or crimped

RATING:

15 Amps

Hands free testing to 5000 VDC max.

Temperature: -70°C to 50°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mueller Electric:](#)

[BU-P5169-2](#)