

Miniature Fuse, 6.3 x 32 mm, Quick-Acting F, GAM T1, 250 VAC, 125 VDC



250 VAC · 125 VDC · Quick-Acting F



GAM  
T1 NNO

### Description

- High breaking capacity

### References

Corresponding Fuseholder 231549P


### Weblinks

[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Detailed request for product](#)

### Technical Data

Rated Voltage	250 VAC, 125 VDC	Resistance to Vibration	acc. to NF C 20-706 / IEC 60068-2-6, test Fc
Rated current	0.16 - 20 A	Shocks	acc. to NF C 20-706 / IEC 60068-2-27
Breaking Capacity	1 kA - 10 kA	Bumps	acc. to NF C 20-729 / IEC 60068-2-29
Characteristic	Quick-Acting F	Salt Mist	acc. to NF C 20-711 / IEC 60068-2-11
Mounting	Fuseholder / Clip		
Admissible Ambient Air Temp.	-40 °C to 125 °C		
Climatic Category	40/125/56 acc. to IEC 60068-1		
Material: Tube	Ceramic		
Unit Weight	3 g		
Storage Conditions	0 °C to 60 °C, max. 70% r.h.		
Product Marking	, Rated current, Rated voltage, HA39		


### Dimension

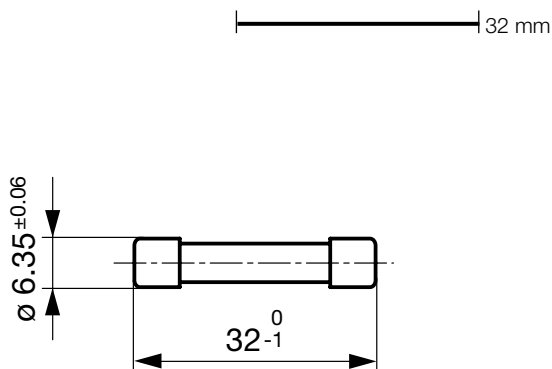

### Pre-Arcing Time

Rated Current In	1.1 x In min.	1.7 x In max.	3.0 x In max.
0.16 A - 20 A	60 min	60 min	10 s

**Time-Current-Curves**

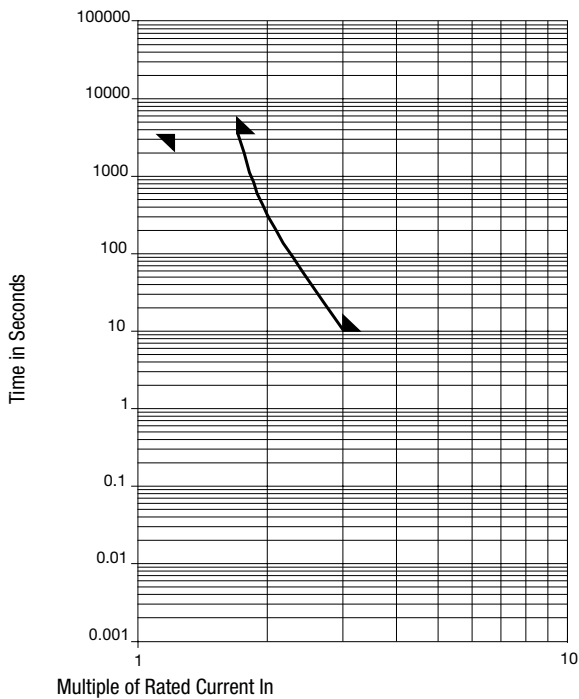

**All Variants**

Rated Current [A]	Rated Voltage [VAC]	Rated Voltage [VDC]	Breaking Capacity	Voltage Drop 1.0 I <sub>n</sub> typ. [mV]	Power Dissipation 1.1 I <sub>n</sub> typ. [mW]	Melting I <sup>2</sup> t 10.0 I <sub>n</sub> typ. [A <sup>2</sup> s]	GAM T1	NNO	Order Number
0.16	250	125	1)	3000	770	0.0021	●		7023.0790
0.25	250	125	1)	2290	870	0.0075	●		7023.0810
0.4	250	125	1)	1800	1000	0.01	●		7023.0830
0.63	250	125	1)	1050	1050	0.44	●	●	7023.0850
1	250	125	1)	770	1170	0.16	●		7023.0870
1.6	250	125	1)	540	1350	0.74	●	●	7023.0890
4	250	125	1)	220	1300	24	●		7023.0930
6.3	250	125	1)	310	3100	27	●		7023.0950
8	250	125	1)	90	1050	9.3	●		7023.0960
10	250	125	1)	85	1350	34	●	●	7023.0970
12.5	250	125	1)	90	1600	62			7023.0980
16	250	125	1)	80	1900	160			7023.0990
20	250	125	1)	75	2000	240			7023.0940

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

1) 10 kA @ 250 VAC , p.f. = 0.7 - 0.8 / 1 kA @ 125 VDC

**Packaging Unit**      Small Box Pack (10 pcs.)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Schurter:

[7023.0990](#) [7023.0980](#) [7023.0870](#)